


Product data sheet

Characteristics

PDL56SW01

Switch - Auxiliary Contact, 125V or 250V, 1-Pole

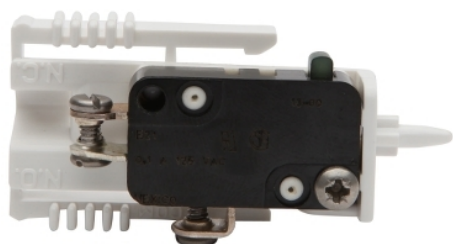

Main

Range of product	56 Series™
Product or component type	Auxiliary contact
Control type	Rotary


Complementary

Material	PC (polycarbonate)
Contacts material	Gold plated
Colour tint	White
Surface finish	Gloss
Rated current	0.05 A 0.1 A
[Ue] rated operational voltage	125 V 250 V
Network frequency	50 Hz
Network number of phases	1 phase
Number of gangs	1 gang
Number of poles	1
Mounting mode	Surface mounted
Ambient air temperature for operation	-40...55 °C
Auxiliary contact composition	1 NO/NC
Quantity per set	Set of 5
Type of packing	Carton

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	0.014 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
EU RoHS Directive	Compliant with Exemptions
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes

Environmental Disclosure	 Product Environmental Profile
Circularity Profile	No need of specific recycling operations