


Product data sheet

Characteristics

PDL56SW01

Switch - Auxiliary Contact, 125V or 250V, 1-Pole

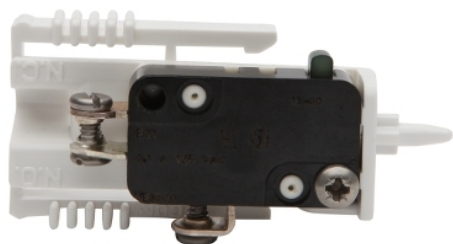

Main

Range of product	56 Series™
Product or component type	Auxiliary contact
Control type	Rotary

Complementary

Material	PC (polycarbonate)
Contacts material	Gold plated
Colour tint	White
Surface finish	Gloss
Rated current	0.05 A 0.1 A
[Ue] rated operational voltage	125 V 250 V
Network frequency	50 Hz
Network number of phases	1 phase
Number of gangs	1 gang
Number of poles	1
Mounting mode	Surface mounted
Ambient air temperature for operation	-40...55 °C
Auxiliary contact composition	1 NO/NC
Quantity per set	Set of 5
Type of packing	Carton

Packing Units

Package 1 Weight	16.000 kg
------------------	-----------

Offer Sustainability

Sustainable offer status	Green Premium product
RECh Regulation	RECh Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile