


Product data sheet

Characteristics

PDLP223H-3A

Protective Box IK10, Pro Series, With lockable lid, Aluminium

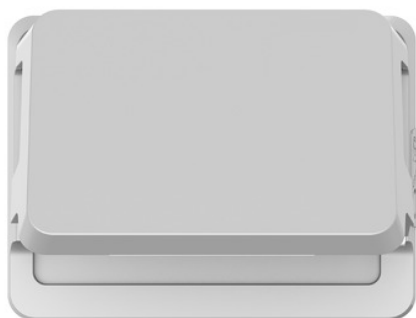

Main

Range	Pro Series
Product brand	PDL
Product or component type	Box
Device application	Protection
Colour	Wall: aluminium
Cover type	Lockable hinged lid
Lock type	1 point locking system
Enclosure type	Enclosure for power outlet

Complementary

Shape	Rectangular
Device mounting	Wall mounted
Mounting mode	Surface mounted
Mounting support	Wall box
Material	Zinc alloy
Installation direction	Horizontal
Fixing mode	By screws
Number of mounting holes	6
Tightening torque	0.53 N.m
Length	150 mm
Depth	45 mm
Height	112 mm
IK degree of protection	IK10
Targeted country	New Zealand

Environment

Ambient air temperature for operation	0...45 °C
---------------------------------------	-----------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	16.7 cm
Package 1 Width	10.5 cm
Package 1 Length	13.0 cm
Package 1 Weight	672.0 g

Offer Sustainability

EU RoHS Directive	Under investigation
-------------------	---------------------