


Product data sheet

Characteristics

PDLP395H4XXUAC-BK

Pro Series, cover frame, 6 switches & 4 sockets, 10 A, Black

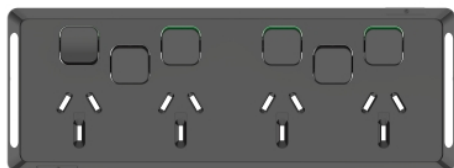

Main

Range	Pro Series
Product or component type	Cover frame
Colour tint	Black (BK)
Type of packing	Polybag

Complementary

Range compatibility	Pro Series switched socket
Product destination	Switched socket
Number of rocker	6
Number of power socket outlets	4
[In] rated current	10 A
Installation direction	Horizontal
Fixing mode	Clip-on
Surface finish	Glossy
Material	PC (polycarbonate): window ABS (acrylonitrile butadiene-styrene): skin
Height	78 mm
Width	212 mm
Depth	9 mm
Net weight	0.032 kg

Environment

Ambient air temperature for operation	0...45 °C
Relative humidity	10...95 %

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	0.9 cm
Package 1 Width	7.8 cm
Package 1 Length	21.2 cm
Package 1 Weight	39.05 g

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations