


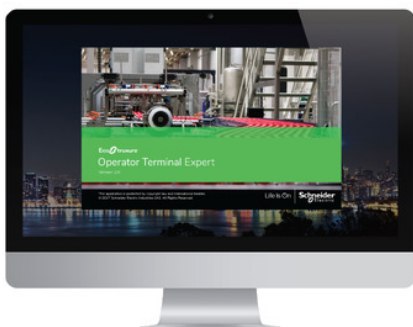

Principales

Gamme de produit	EcoStruxure operator terminal Expert
Type de produit ou équipement	Licence
Format	Papier
Type de logiciel	Add-on
Type de licence	Licence nœud verrouillé
Variante	Runtime
Version logicielle	V3.5
Operating system requirement	Windows 10 64 bits
Configuration requise	8 Go de RAM 30 Go d'espace disque
Langue utilisateur	Anglais Italien Chinois Espagnol Français Allemand Portugais Coréen

Complémentaires

Catégorie de la licence	Permanent
Protocole de communication	Esclave CANopen Couzet Automation millenium 3 FBD Emerson Industrial Automation maître Modbus SIO Emerson Industrial Automation Modbus TCP master Control Techniques maître Modbus SIO Control Techniques Modbus TCP master Emerson Process Management ROC Plus Ethernet Emerson Process Management ROC SIO HTTP IPsec Mitsubishi A séries Ethernet Mitsubishi série FX CPU direct Mitsubishi série FX Ethernet Mitsubishi iQ-R/F series Ethernet SLMP client Mitsubishi Série Q CPU direct Mitsubishi Série Q QnU CPU Ethernet Mitsubishi Série Q/QnA en série Modbus Organization maître Modbus ASCII SIO Modbus Organization maître Modbus SIO Modbus Organization esclave Modbus SIO Modbus Organization Modbus TCP master Modbus Organization esclave Modbus TCP Omron CS/CJ/CP series host link Omron CS/CJ/CP/NX series Ethernet Omron CS/CJ/NJ/NX series Ethernet/IP OPC UA server Esclave Profibus DP Rockwell Automation Ethernet IP Rockwell Automation DF1 Rockwell Automation DH485 Schneider Electric maître Modbus SIO Schneider Electric Modbus TCP master Schneider Electric Modbus TCP master via USB Schneider Electric Machine expert network Schneider Electric PacDrive Schneider Electric Uni-Telway Schneider Electric Zelio Logic Siemens Simatic S7 Ethernet Siemens Simatic S7 MPI direct Siemens TIA portal Ethernet websocket
Version logicielle précédente	V3.4
Fonction du logiciel	Web viewer Alarms and events Blockly script Convertors Import export with CSV, tab and period delimiter Data and operation logging Multi language development Multi language tables Object binding and properties Target binding and properties Recipes Screens (contents and folders) Security (levels, project, users) System keypad Text script Color themes Variable (arrays, binding, properties, structures) OPC UA Server
Accessoires associés	Windows compatible PC
Compatibilité de gamme	Harmony GTU Harmony GTUX Harmony ST6 Harmony STM6 Harmony STO7 Harmony iPC
Option d'hébergement	On-device
Taille de la licence	Single (1 station)

Processor requirement	Intel core i3 8th generation Intel core i5 8th generation
Résolution de l'affichage	320 x 240 pixels HVGA minimum 3840 x 2160 pixels 4K UHD maximum