


Product data sheet

Characteristics

33671

MN undervoltage release, Compact NS 630b to 3200, 200 VDC to 250 VDC, 200 VAC to 250 VAC 50/60 Hz

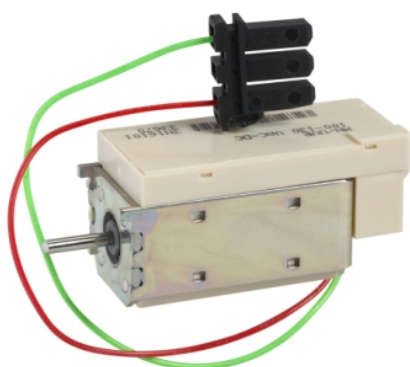

Main

Range	ComPacT
Range of product	ComPacT NS630b...1600 new generation ComPacT NS1600b...3200 new generation
Device short name	MN
Product or component type	Voltage release
Device application	Control
Voltage release type	Opening coil Undervoltage release
Control type	Standard
[Uc] control circuit voltage	200...250 V AC 50/60 Hz 200...250 V DC
Circuit breaker mounting mode	Fixed
Range compatibility	ComPacT ComPacT NS630b...1600 ComPacT ComPacT NS1600b...3200

Complementary

Operating threshold	0.35...0.7 x Un opening 0.85 x Un closing
Response time	90 ms +/- 5 % for Compact NS630b...1600 90 ms +/- 5 % for Compact NS1600b...3200 40 ms +/- 5 % for MasterPact NT 90 ms +/- 5 % for MasterPact NW
Supply holding power	4.5 VA
Accessory / separate part category	Spare part for MasterPact NT Spare part for MasterPact NT NAVY Spare part for MasterPact NW Spare part for MasterPact NW NAVY Spare part for ComPacT NS630b...1600 new generation Spare part for ComPacT NS1600b...3200 new generation

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.5 cm
Package 1 Width	6.0 cm
Package 1 Length	8.1 cm
Package 1 Weight	150.0 g
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	9.0 cm
Package 2 Width	13.0 cm
Package 2 Length	18.5 cm
Package 2 Weight	1.6 kg
Unit Type of Package 3	S03

Number of Units in Package 3	120
Package 3 Height	30.0 cm
Package 3 Width	30.0 cm
Package 3 Length	40.0 cm
Package 3 Weight	19.435 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
Environmental Disclosure	 Product Environmental Profile
Circularity Profile	 End Of Life Information

Contractual warranty

Warranty	18 months
----------	-----------