


Product data sheet

Characteristics

EZAUX10

auxiliary switch AX, EasyPact EZC 100,
EasyPact CVS 100BS, 1 common point
changeover contact

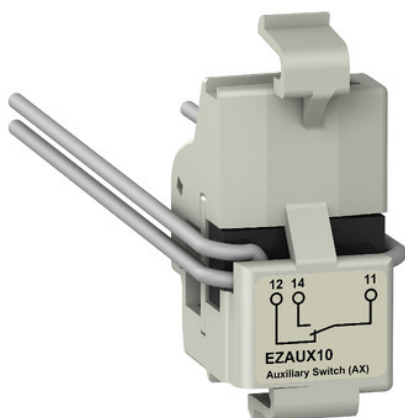

Main

Range of product	EZC100
Range	EasyPact
Device short name	AX
Product or component type	Switch
Device application	Signalling
Range compatibility	EasyPact EZC circuit breaker
Signal contacts composition	1 NO/NC



Complementary

Auxiliary contacts type	Standard
[I _{th}] conventional free air thermal current	5 A
[I _e] rated operational current	AC-12: 3 A at 250 V AC 50/60 Hz AC-12: 5 A at 125 V AC 50/60 Hz AC-12: 5 A at 24 V AC 50/60 Hz AC-12: 5 A at 48 V AC 50/60 Hz AC-15: 2 A at 250 V AC 50/60 Hz AC-15: 3 A at 125 V AC 50/60 Hz AC-15: 5 A at 24 V AC 50/60 Hz AC-15: 5 A at 48 V AC 50/60 Hz DC-12: 0.2 A at 250 V DC DC-12: 0.4 A at 125 V DC DC-12: 2.5 A at 48 V DC DC-12: 4 A at 24 V DC DC-14: 0.2 A at 250 V DC DC-14: 0.4 A at 125 V DC DC-14: 1 A at 48 V DC DC-14: 3 A at 24 V DC
Minimum load	10 mA at 24 V
Auxiliary connection terminal	Lead wire

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.5 cm
Package 1 Width	7.0 cm
Package 1 Length	8.5 cm
Package 1 Weight	40.0 g

Offer Sustainability

REACH Regulation	 REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant  EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins

Contractual warranty

Warranty	18 months
----------	-----------