


Product data sheet

Characteristics

EZAUX11

auxiliary and alarm switch AL AX, EasyPact
EZC 100, EasyPact CVS 100BS, 2 common
point changeover contacts

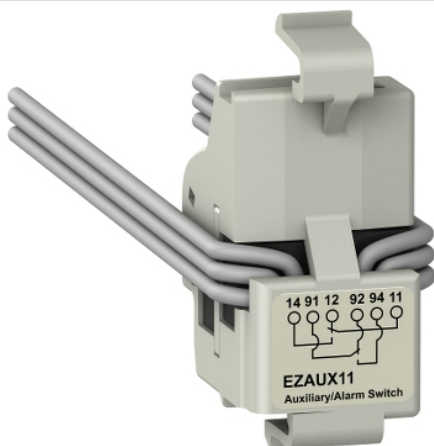

Main

| | |
|-----------------------------|------------------------------|
| Range of product | EZC100 |
| Range | EasyPact |
| Device short name | AL[RETURN]AX |
| Product or component type | Switch |
| Device application | Signalling Alarm |
| Range compatibility | EasyPact EZC circuit breaker |
| Signal contacts composition | 2 NO/NC |



Complementary

| | |
|----------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Auxiliary contacts type | Standard |
| [I _{th}] conventional free air thermal current | 5 A |
| [I _e] rated operational current | AC-12: 3 A at 250 V AC 50/60 Hz AC-12: 5 A at 125 V AC 50/60 Hz AC-12: 5 A at 24 V AC 50/60 Hz AC-12: 5 A at 48 V AC 50/60 Hz AC-15: 2 A at 250 V AC 50/60 Hz AC-15: 3 A at 125 V AC 50/60 Hz AC-15: 5 A at 24 V AC 50/60 Hz AC-15: 5 A at 48 V AC 50/60 Hz DC-12: 0.2 A at 250 V DC DC-12: 0.4 A at 125 V DC DC-12: 2.5 A at 48 V DC DC-12: 4 A at 24 V DC DC-14: 0.2 A at 250 V DC DC-14: 0.4 A at 125 V DC DC-14: 1 A at 48 V DC DC-14: 3 A at 24 V DC |
| Minimum load | 10 mA at 24 V |
| Auxiliary connection terminal | Lead wire |

Packing Units

| | |
|------------------------------|---------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Height | 2.54 cm |
| Package 1 Width | 7.11 cm |
| Package 1 Length | 8.38 cm |
| Package 1 Weight | 0.06 kg |

Offer Sustainability

| | |
|----------------------------|---------------------------------------------------------------------------------------------------------------------------------|
| REACH Regulation |  REACH Declaration |
| REACH free of SVHC | Yes |
| EU RoHS Directive | Compliant  EU RoHS Declaration |
| Toxic heavy metal free | Yes |
| Mercury free | Yes |
| China RoHS Regulation |  China RoHS Declaration |
| RoHS exemption information |  Yes |
| WEEE | The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|