



Teknisk informasjon

Produktspekter	Harmony XB5
Salg per udelelig kvantitet	1

Komplementær

Panel Thickness with accessory	1,5...2,5 mm
Produkt eller type komponent	Metal protection cover
Materiale	Metall
Tilbehør / separat del kategori	Beskyttelsesutstyr
Kompatibilitet	Panel mounted RJ45 port XB5P Panel mounted USB port XB5P
IP-grad	IP65 conforming to IEC 60529 IP67 conforming to IEC 60529 IP69K i samsvar med IEC 60529
Farge	Sølv

Forpakkingsinformasjon

Enhetstype pakke 1	PCE
Antall enheter i pakke 1	1
Pakke 1 Høyde	2,5 cm
Pakke 1 Bredde	4 cm
Pakke 1 Vekt	6 cm
Package 1 Weight	13 g
Enhetstype pakke 2	S02
Antall enheter i pakke 2	100
Pakke 2 Høyde	15 cm
Pakke 2 Bredde	30 cm
Pakke 2 Lengde	40 cm
Pakke 2 Vekt	1,625 kg

Bærekraftig

REACH-regelverk	REACH-erklæring
REACH fri for SVHC	Ja
EU RoHS-direktiv	Proaktivt i samsvar (Produktet inngår ikke i EUs RoHS direktivet)
Kvikksølvfri	Ja
Kinas RoHS-forskrift	Kinas RoHS-Erklæring
Informasjon om RoHS-unntak	Ja


Logistisk informasjon

Opprinnelsesland	DE
------------------	----

Garantiperiode

Garanti	18 måneder
---------	------------


Dimensions

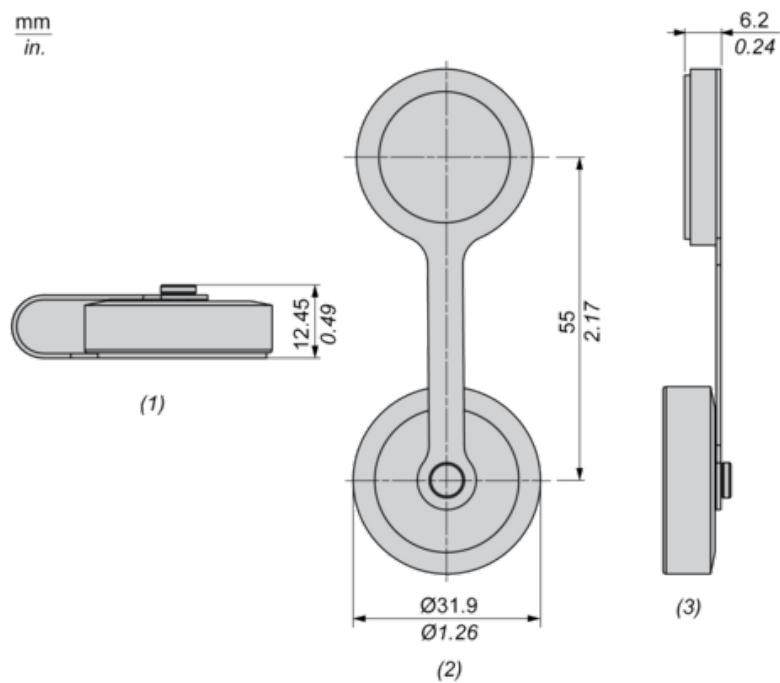

- (1) Side view - Closed
(2) Front View - Open
(3) Side view - Open

Panel Cut-out for Protective Cover (Finished Holes, Ready for Installation)

Connection by Screw Clamp Terminals or Plug-in Connectors

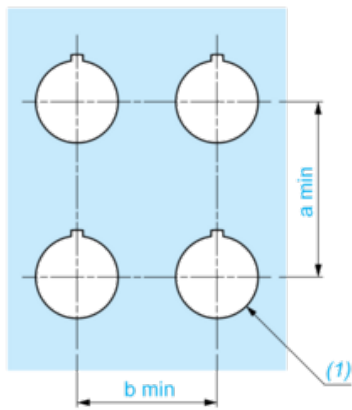

(1) Diameter on finished panel or support

Connections	a in mm	a in in.	b in mm	b in in.
By screw clamp terminals or plug-in connector	50	1.97	40	1.57