



Osnovne informacije

Grupa proizvoda	Harmony Electromechanical Relays
Kratko ime uređaja	RXZ
Tip proizvoda ili komponente	Utičnica
Kompatibilnost proizvoda	Utični relej RXM sa 3 C/O kontakt
Tip kontakata i sastav	3 C/O
[ith] dozvoljena termička struja u vazduhu	10 A

Dopunske informacije

Oblik pina	Ravni
[ue] nazivni napon	< 250 V
Raspored klema	Odvojeni
Povezivanje - priključci	Priključak, 1 x 0.25...1 x 2.5 mm ² (AWG 22...AWG 14) fleksibilni sa kablovskim završetkom Priključak, 2 x 0.25...2 x 1 mm ² (AWG 22...AWG 17) fleksibilni sa kablovskim završetkom Priključak, 1 x 0.5...1 x 2.5 mm ² (AWG 20...AWG 14) jednožični bez kablovskog završetka Priključak, 2 x 0.5...2 x 1.5 mm ² (AWG 20...AWG 16) jednožični bez kablovskog završetka
Moment pritezanja	< 1 N.m za M3
Način fiksiranja	Sa zavrtnjem bez matice (panel) Sistem na klik (35 mm simetrična DIN šina)
[uimp] nazivni napon impulsa	4 kV
Kategorija prenapona	III
Stepen zaprljanosti	3
Prodaja po nedeljivim količinama	10
Širina	27 mm
Masa proizvoda	0,066 kg

Okruženje

Ip stepen zaštite	IP20 conforming to IEC 60529
Dielektrična snaga	2500 V
Standardi	IEC 61984
Sertifikacija proizvoda	UL[RETURN]Lloyd's[RETURN]CSA
Označavanje	CE
Temperatura okoline za skladištenje	-40...85 °C
Temperatura okoline za rad uređaja	-40...55 °C

Pakovanje

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2,7 cm
Package 1 Width	6,1 cm
Package 1 Length	8,2 cm
Package 1 Weight	61 g
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	11,6 cm
Package 2 Width	6,8 cm
Package 2 Length	14 cm
Package 2 Weight	624 g
Unit Type of Package 3	S02
Number of Units in Package 3	200
Package 3 Height	15 cm
Package 3 Width	30 cm
Package 3 Length	40 cm
Package 3 Weight	10,7 kg


Održivost ponude

Status održive ponude	Green Premium proizvod
Propis REACH	 REACH Deklaracija
REACH bez SVHC	Da
EU RoHS direktiva	Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)  EU RoHS deklaracija
Bez toksičnih teških metala	Da
Bez žive	Da
RoHS regulativa za Kinu	 RoHS Deklaracija Za Kinu
Informacije o RoHS izuzecima	 Da
Izjava o zaštiti okoliša	 Profil Ekološke Prihvatljivosti Proizvoda
Profil cirkularnosti	Nema potrebe za namenskim operacijama recikliranja
WEEE	Ovaj proizvod je na tržištima Evropske unije neophodno odložiti u skladu sa specifičnim smernicama za prikupljanje otpada i nikako ne sme da dospe u kontejnere za otpatke.

Ugovorna garancija


Garancija	18 meseci
-----------	-----------

Dimensions

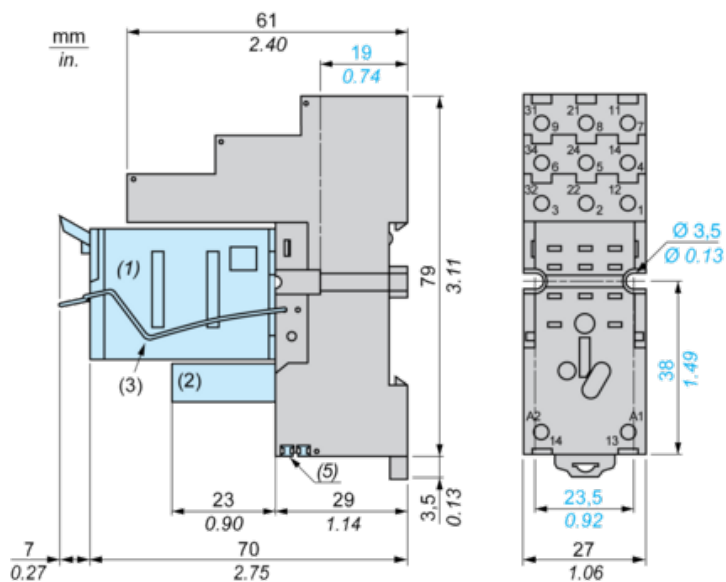

- (1) Relays
- (2) Protection module
- (3) Maintaining clamp
- (4) 2 elongated holes $\varnothing 3.5$ mm x 6.5 mm / $\varnothing 0.13$ in. x 0.25 in.
- (5) 2 bus jumpers


Wiring Diagram

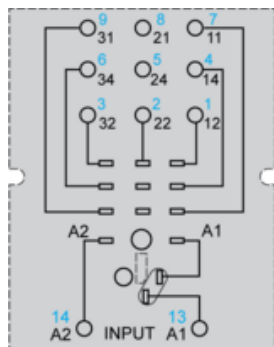

Symbols shown in blue correspond to Nema marking.

Bus Jumpers Mounting on Sockets with Separate Contacts

Example of RXZS2 bus jumper mounting on sockets (view from below)

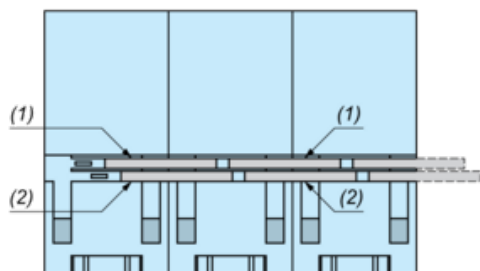

- (1) 2 bus jumpers (polarity A2)
- (2) 2 bus jumpers (polarity A1)