


Tehničke karakteristike proizvoda

Karakteristike

ISM20450

OptiLine 45 - blok za povezivanje - 30x75x40

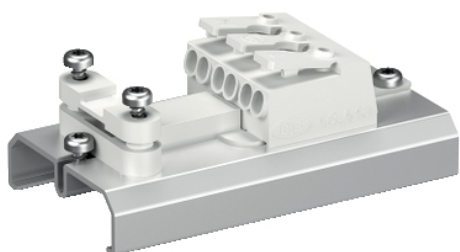

Osnovne informacije

Grupa proizvoda	OptiLine 45
Product type	Priključni blok
Quantity package 1 / unit	1 deo

Dopunske informacije

Sastav uređaja	Prednji poklopac Zavrtanj Element protiv naprezanja
Product material	PC (polikarbonat) Aluminijum
Visina	30 mm
Širina	75 mm
Dubina	40 mm

Okruženje

Operating temperature	-5...60 °C
Ip stepen zaštite	IP30

Pakovanje

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2,5 cm
Package 1 Width	14,0 cm
Package 1 Length	18,0 cm
Package 1 Weight	42,0 g
Unit Type of Package 2	S03
Number of Units in Package 2	100
Package 2 Height	30,0 cm
Package 2 Width	30,0 cm
Package 2 Length	40,0 cm
Package 2 Weight	4,687 kg

Održivost ponude

EU RoHS direktiva	Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)  EU RoHS deklaracija
Bez toksičnih teških metala	Da
Bez žive	Da
RoHS regulativa za Kinu	 RoHS Deklaracija Za Kinu
Informacije o RoHS izuzecima	 Da