


Tehničke karakteristike proizvoda

Karakteristike

MGU0.822.AZL

Unica -zamenska lampica - 250 V AC - plava -
LED lampica

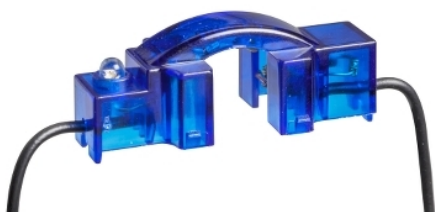

Osnovne informacije

Grupa proizvoda	Unica
Pribor / posebna kategorija	Pribor za zamenu
Tip proizvoda ili komponente	Zamenska LED lampica
Ime dekorativnog elementa	Unica
Boja bloka	Plava
Tip sijalice	LED lampica

Dopunske informacije

[ue] nazivni radni napon	127/230 V AC za prekidač
Struja potrošnje	0.15 mA
Povećanje temperature	Maksimalno +15 °C iznad temperature okoline uređaja
Temperatura okoline za rad uređaja	-20...40 °C
Masa proizvoda	0,0027 kg

Okruženje

Standardi	UNE 60669-1
-----------	-------------

Pakovanje

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1,000 cm
Package 1 Width	1,500 cm
Package 1 Length	3,500 cm
Package 1 Weight	2,900 g
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	6,500 cm
Package 2 Width	8,000 cm
Package 2 Length	8,500 cm
Package 2 Weight	55,000 g
Unit Type of Package 3	S01
Number of Units in Package 3	90
Package 3 Height	15,000 cm
Package 3 Width	15,000 cm
Package 3 Length	40,000 cm
Package 3 Weight	644,000 g

Održivost ponude

Status održive ponude	Green Premium proizvod
Propis REACH	 REACH Deklaracija
EU RoHS direktiva	У складу са изузецима
Bez žive	Da
RoHS regulativa za Kinu	 RoHS Deklaracija Za Kinu
Informacije o RoHS izuzecima	 Da
Izjava o zaštiti okoliša	 Profil Ekološke Prihvatljivosti Proizvoda
Profil cirkularnosti	Nema potrebe za namenskim operacijama recikliranja
WEEE	Ovaj proizvod je na tržištima Evropske unije neophodno odložiti u skladu sa specifičnim smernicama za prikupljanje otpada i nikako ne sme da dospe u kontejnere za otpatke.

Ugovorna garancija

Garancija	18 meseci
-----------	-----------