


Tehničke karakteristike proizvoda

Karakteristike

NU173454

Ugradna kutija 3 kolone antracit

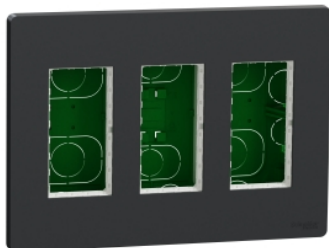

Osnovne informacije

Grupa proizvoda	New Unica
Tip proizvoda ili komponente	Radna stanica
Broj modula	3 x 4 modules
Način pričvršćivanja	Embedment Kukicama
Nijansa boje	Antracit

Dopunske informacije

Zaštitna oprema	Ram Montažni ram
Montaža uređaja	Ugradno
Kablovski uvod	6 definisani otvori 20 mm 6 definisani otvori 25 mm 2 dno cable entries 45 x 25 mm 20 mm 4 dno cable entries 50 x 35 mm 25 mm
Otpornost na vatru	850 °C, vreme gašenja <30 sekundi
Materijal	ABS (akrilonitril-butadien-stiren): separator PC: kutija ABS (akrilonitril-butadien-stiren): dekorativni ram
Dubina	62 mm
Širina	230 mm
Visina	165 mm
Masa proizvoda	0,401 kg
Otpornost na hemijske supstance	Otporan na alkohol (70%) Otporan na alkohol (96%) Otporan na A-mlečnu kiselinu Otporan na razblaženi kvarterni amonijum Otporan na razblaženo izbeljivač Otporan na razblažen amonijak Otporan na vodu sa sapunom Otporan na čistač kristala Otporan na vodonik peroksid 10 zapremina Otporan na heksan

Okruženje

Ik stepen zaštite	IK04
-------------------	------

Pakovanje

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	8,0 cm
Package 1 Width	18,0 cm
Package 1 Length	25,0 cm
Package 1 Weight	520,0 g

Unit Type of Package 2	S04
Number of Units in Package 2	14
Package 2 Height	30,0 cm
Package 2 Width	40,0 cm
Package 2 Length	60,0 cm
Package 2 Weight	8,001 kg
Unit Type of Package 3	P06
Number of Units in Package 3	56
Package 3 Height	80,0 cm
Package 3 Width	80,0 cm
Package 3 Length	60,0 cm
Package 3 Weight	39,676 kg

Održivost ponude

EU RoHS direktiva	Nije primenljivo, izvan zakonskog okvira direktive EU RoHS
-------------------	--