

## Tehničke karakteristike proizvoda

### Karakteristike

## XVC6M2K

60mm svetlosna kolona CN montaža na bazu  
100-240VAC



### Osnovne informacije

|                                       |                                             |
|---------------------------------------|---------------------------------------------|
| Grupa proizvoda                       | Harmony XVC6                                |
| Tip proizvoda ili komponente          | Kompletno ožičena monolitna svetleća kolona |
| Tip baze svetleće kolone ili semafora | 2 svetleće jedinice                         |
| Zvučni signal                         | Bez                                         |
| Prečnik za montiranje                 | 60 mm                                       |
| Ime komponente                        | XVC                                         |
| Svetlosni izvor                       | LED trajna crvena<br>LED trajna narandžasta |
| [us] nazivni napon                    | 100...240 V                                 |
| Tip kola napajanja                    | AC                                          |

### Dopunske informacije

|                                              |                                                                                                                     |
|----------------------------------------------|---------------------------------------------------------------------------------------------------------------------|
| Materijal                                    | Polikarbonat: svetleća jedinica<br>ABS (akrilonitril-butadien-stiren): bazi<br>PBT + ABS (UL94-V0): gornji poklopac |
| Montaža proizvoda                            | Na bazi                                                                                                             |
| Poprečni presek kabla                        | 0,33 Mm <sup>2</sup><br>0,83 mm <sup>2</sup>                                                                        |
| Awg mera (američki standard za prečnik žice) | AWG 22<br>AWG 18                                                                                                    |
| Dužina kabla                                 | 750 Mm<br>850 mm                                                                                                    |
| Označavanje                                  | CE                                                                                                                  |
| [uimp] nazivni napon impulsa                 | 4 kV                                                                                                                |
| Struja potrošnje                             | 50 mA                                                                                                               |
| Masa proizvoda                               | 0,5 kg                                                                                                              |
| Visina                                       | 272 mm                                                                                                              |

### Okruženje

|                                        |                                                             |
|----------------------------------------|-------------------------------------------------------------|
| Standardi                              | EN/IEC 60947-5-1<br>EN/IEC 60947-1                          |
| Sertifikacija proizvoda                | UL                                                          |
| Tretman zaštite                        | TC                                                          |
| Temperatura okoline za skladištenje    | -35...70 °C                                                 |
| Temperatura okoline za rad uređaja     | -10...50 °C                                                 |
| Klasa zaštite protiv električnog udara | Klasa I u skladu sa EN/IEC 61140                            |
| Ip stepen zaštite                      | IP54 instalaciji na ravnu površinu u skladu sa EN/IEC 60529 |

### Pakovanje

|                              |         |
|------------------------------|---------|
| Unit Type of Package 1       | PCE     |
| Number of Units in Package 1 | 1       |
| Package 1 Height             | 8,7 cm  |
| Package 1 Width              | 8,5 cm  |
| Package 1 Length             | 50,0 cm |
| Package 1 Weight             | 678,0 g |

|                              |           |
|------------------------------|-----------|
| Unit Type of Package 2       | S04       |
| Number of Units in Package 2 | 12        |
| Package 2 Height             | 30,0 cm   |
| Package 2 Width              | 40,0 cm   |
| Package 2 Length             | 60,0 cm   |
| Package 2 Weight             | 9,388 kg  |
| Unit Type of Package 3       | P12       |
| Number of Units in Package 3 | 240       |
| Package 3 Height             | 50,0 cm   |
| Package 3 Width              | 80,0 cm   |
| Package 3 Length             | 120,0 cm  |
| Package 3 Weight             | 199,76 kg |

## Održivost ponude

|                              |                                                                                                                                                                             |
|------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| EU RoHS direktiva            | Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)                                                                                                |
| Bez žive                     | Da                                                                                                                                                                          |
| RoHS regulativa za Kinu      |  <a href="#">RoHS Deklaracija Za Kinu</a>                                                  |
| Informacije o RoHS izuzecima |  <a href="#">Da</a>                                                                        |
| Izjava o zaštiti okoliša     |  <a href="#">Profil Ekološke Prihvatljivosti Proizvoda</a>                                 |
| Profil cirkularnosti         |  <a href="#">Informacije O Kraju Radnog Veka</a>                                           |
| WEEE                         | Ovaj proizvod je na tržištima Evropske unije neophodno odložiti u skladu sa specifičnim smernicama za prikupljanje otpada i nikako ne sme da dospe u kontejnere za otpatke. |


## Ugovorna garancija

|           |           |
|-----------|-----------|
| Garancija | 18 meseci |
|-----------|-----------|

## Pre-assembled and Pre-wired Tower Light

### Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get b dimension.

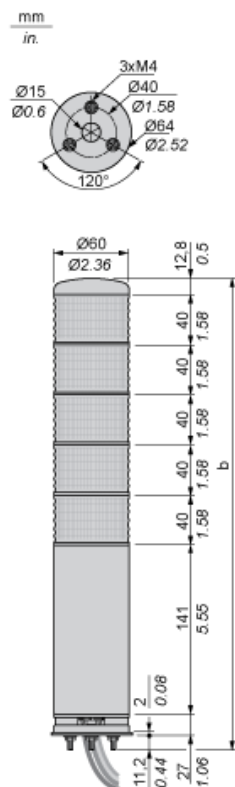

| No. of illuminated units | b (mm) | b (in.) |
|--------------------------|--------|---------|
| 1 stage                  | 232    | 9.13    |
| 2 stages                 | 272    | 10.71   |
| 3 stages                 | 312    | 12.28   |
| 4 stages                 | 352    | 13.86   |
| 5 stages                 | 392    | 15.43   |

---

Pre-assembled and Pre-wired Tower Light

---

Mounting on Horizontal Support (Direct or with Fixing Plate)

Panel cut-out

