

Tehničke karakteristike proizvoda

Karakteristike

XVC6M4K

60mm svetlosna kolona CNZP montaža na bazu 100-240VAC



Osnovne informacije

Grupa proizvoda	Harmony XVC6
Tip proizvoda ili komponente	Kompletno ožičena monolitna svetleća kolona
Tip baze svetleće kolone ili semafora	4 svetleće jedinice
Zvučni signal	Bez
Prečnik za montiranje	60 mm
Ime komponente	XVC
Svetlosni izvor	LED trajna crvena LED trajna narandžasta LED trajna zelena LED trajna plava
[us] nazivni napon	100...240 V
Tip kola napajanja	AC

Dopunske informacije

Materijal	Polikarbonat: svetleća jedinica ABS (akrilonitril-butadien-stiren): bazi PBT + ABS (UL94-V0): gornji poklopac
Montaža proizvoda	Na bazi
Poprečni presek kablova	0,83 Mm ² 0,33 mm ²
Awg mera (američki standard za prečnik žice)	AWG 22 AWG 18
Dužina kablova	750 Mm 850 mm
Označavanje	CE
[uimp] nazivni napon impulsa	4 kV
Struja potrošnje	75 mA
Masa proizvoda	0,6 kg
Visina	352 mm

Okruženje

Standardi	EN/IEC 60947-5-1 EN/IEC 60947-1
Sertifikacija proizvoda	UL
Tretman zaštite	TC
Temperatura okoline za skladištenje	-35...70 °C
Temperatura okoline za rad uređaja	-10...50 °C
Klasa zaštite protiv električnog udara	Klasa I u skladu sa EN/IEC 61140
Ip stepen zaštite	IP54 instalaciji na ravnu površinu u skladu sa EN/IEC 60529

Pakovanje

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	8,3 cm
Package 1 Width	8,3 cm
Package 1 Length	50,0 cm
Package 1 Weight	760,0 g
Unit Type of Package 2	S04
Number of Units in Package 2	1
Package 2 Height	30,0 cm
Package 2 Width	40,0 cm
Package 2 Length	60,0 cm
Package 2 Weight	1,252 kg
Unit Type of Package 3	P12
Number of Units in Package 3	240
Package 3 Height	50,0 cm
Package 3 Width	80,0 cm
Package 3 Length	120,0 cm
Package 3 Weight	219,44 kg

Održivost ponude

EU RoHS direktiva	Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)
Bez žive	Da
RoHS regulativa za Kinu	 RoHS Deklaracija Za Kinu
Informacije o RoHS izuzecima	 Da
Izjava o zaštiti okoliša	 Profil Ekološke Prihvatljivosti Proizvoda
Profil cirkularnosti	 Informacije O Kraju Radnog Veka
WEEE	Ovaj proizvod je na tržištima Evropske unije neophodno odložiti u skladu sa specifičnim smernicama za prikupljanje otpada i nikako ne sme da dospe u kontejnere za otpatke.


Ugovorna garancija

Garancija	18 meseci
-----------	-----------

Pre-assembled and Pre-wired Tower Light

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get b dimension.

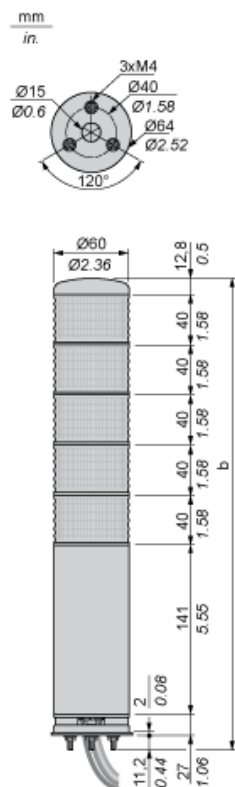

No. of illuminated units	b (mm)	b (in.)
1 stage	232	9.13
2 stages	272	10.71
3 stages	312	12.28
4 stages	352	13.86
5 stages	392	15.43

Pre-assembled and Pre-wired Tower Light

Mounting on Horizontal Support (Direct or with Fixing Plate)

Panel cut-out

