

Tehničke karakteristike proizvoda

Karakteristike

XZCR1509041J2

spojni kabl XZ - muški ravni M12 4-pinski -
ženski ravni M8 4-pinski - PUR 2m



Osnovne informacije

Pribor / posebna kategorija	Pribor za kabliranje
Pribor / posebni tip	Spojni kabl

Dopunske informacije

Spojni kabl - kraj 1	M12 muški 4 pina ravni sa za zavrtnanje
Spojni kabl - kraj 2	M8 ženski 4 pina ravni sa za zavrtnanje
Sastav kabla	4 x 0.34 mm ²
Dužina kabla	2 m
Izolacioni materijal žice	PUR
Spoljašnji prečnik kabla	5,2 mm
[ue] nazivni radni napon	60 V AC 75 V DC
[in] nazivna struja	4 A
Otpornost izolacije	>= 1000 MOhm
Maksimalna otpornost kroz priključke	5000 mΩ
Masa proizvoda	0,09 kg

Okruženje

Ip stepen zaštite	IP67 IP65 IP69K
Sertifikacija proizvoda	cULus
Temperatura okoline za rad	-35...90 °C promenljiva -5...90 °C promenljiva
Temperatura okoline za skladištenje	-35...100 °C

Pakovanje

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1,500 cm
Package 1 Width	18,000 cm
Package 1 Length	20,000 cm
Package 1 Weight	83,000 g
Unit Type of Package 2	S02
Number of Units in Package 2	40

Package 2 Height	15,000 cm
Package 2 Width	30,000 cm
Package 2 Length	40,000 cm
Package 2 Weight	3,644 kg


Održivost ponude

Status održive ponude	Green Premium proizvod
Propis REACH	 REACH Deklaracija
EU RoHS direktiva	Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)
Bez žive	Da
Informacije o RoHS izuzecima	 Da

Ugovorna garancija

Garancija	18 meseci
-----------	-----------

Dimensions

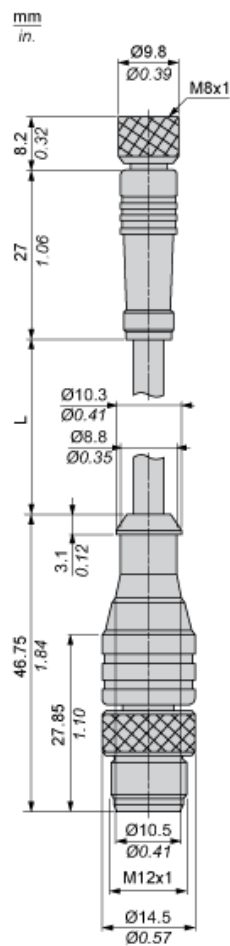

L : Length of cable

Connections and Schemes

