


# Tehničke karakteristike proizvoda

## Karakteristike

# ISM10551

OptiLine 45 - unutrašnji ugao - PC/ABS -  
aluminijum metalik

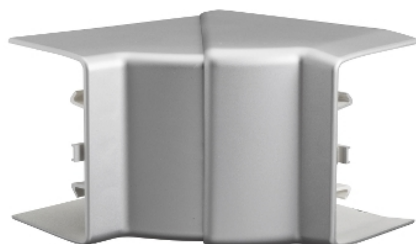

## Osnovne informacije

|                               |                    |
|-------------------------------|--------------------|
| Grupa proizvoda               | OptiLine 45        |
| Kablovski instalacioni sistem | Parapetni razvod   |
| Product type                  | Unutrašnji ugao    |
| Colour                        | Aluminijum metalik |
| Quantity package 1 / unit     | Set od 1           |

## Dopunske informacije

|                              |                      |
|------------------------------|----------------------|
| Materijal parapetnog razvoda | Aluminijum           |
| Dimenzije parapetnog razvoda | 185 x 55 mm          |
| Način pričvršćivanja         | Zatvaranje sa klikom |
| Product material             | PC/ABS ofarban       |
| Dužina                       | 117 mm               |
| Visina                       | 194 mm               |
| Širina                       | 117 mm               |

## Okruženje

|                       |                                                                                                                             |
|-----------------------|-----------------------------------------------------------------------------------------------------------------------------|
| Standardi             | 73/23/EEC<br>93/68/EEC<br>EN 50085-1:2005<br>EN 50085-1:2013/A1<br>EN 50085-2-1:2006<br>EN 50085-2-1:2011/A1<br>NF C 68-102 |
| Operating temperature | -25...60 °C                                                                                                                 |
| Ip stepen zaštite     | IP30                                                                                                                        |
| Ik stepen zaštite     | IK07                                                                                                                        |

## Pakovanje

|                              |         |
|------------------------------|---------|
| Unit Type of Package 1       | PCE     |
| Number of Units in Package 1 | 1       |
| Package 1 Height             | 19,4 cm |
| Package 1 Width              | 11,7 cm |
| Package 1 Length             | 11,7 cm |
| Package 1 Weight             | 140 g   |
| Unit Type of Package 2       | BAG     |
| Number of Units in Package 2 | 10      |
| Package 2 Height             | 30 cm   |
| Package 2 Width              | 29,9 cm |
| Package 2 Length             | 39,8 cm |

|                              |           |
|------------------------------|-----------|
| Package 2 Weight             | 1,871 kg  |
| Unit Type of Package 3       | PAL       |
| Number of Units in Package 3 | 80        |
| Package 3 Height             | 45 cm     |
| Package 3 Width              | 80 cm     |
| Package 3 Length             | 120 cm    |
| Package 3 Weight             | 26,968 kg |

### Održivost ponude

|                              |                                                                                                                    |
|------------------------------|--------------------------------------------------------------------------------------------------------------------|
| Status održive ponude        | Green Premium proizvod                                                                                             |
| Propis REACh                 | <a href="#">📄 REACh Deklaracija</a>                                                                                |
| REACh bez SVHC               | Da                                                                                                                 |
| EU RoHS direktiva            | Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS) <a href="#">📄 EU RoHS deklaracija</a> |
| Bez toksičnih teških metala  | Da                                                                                                                 |
| Bez žive                     | Da                                                                                                                 |
| RoHS regulativa za Kinu      | <a href="#">📄 RoHS Deklaracija Za Kinu</a>                                                                         |
| Informacije o RoHS izuzecima | <a href="#">📄 Da</a>                                                                                               |
| Izjava o zaštiti okoliša     | <a href="#">📄 Profil Ekološke Prihvatljivosti Proizvoda</a>                                                        |
| Profil cirkularnosti         | Nema potrebe za namenskim operacijama recikliranja                                                                 |

### Ugovorna garancija

|           |           |
|-----------|-----------|
| Garancija | 18 months |
|-----------|-----------|