


Tehničke karakteristike proizvoda

Karakteristike

LV429030

zaštitna jedinica - TMD - 100 A - 3P 3d

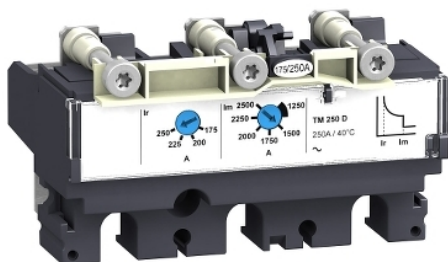

Osnovne informacije

Grupa proizvoda	Compact
Grupa proizvoda	ComPact NSX100...250
Tip proizvoda ili komponente	Zaštitna jedinica
Ime zaštitne jedinice	TM-D
Tehnologija zaštitne jedinice	Termomagnetna
Kompatibilnost grupe proizvoda	Compact NSX100 Compact NSX160 Compact NSX250
Primena uređaja	Razvod električne energije
Number of poles	3P
Opis zaštićenih polova	3t
Funkcija zaštitne jedinice	Li
Tip zaštite	L : for zaštita od preopterećenja (termičkog) I : for zaštita od kratkog spoja
Trip unit rated current	100 A pri 40 °C
[ue] nazivni napon	690 V AC 50/60 Hz
Tip mreže	AC
Mrežna frekvencija	50/60 Hz

Dopunske informacije

Long-time pick-up adjustment type Ir (thermal protection)	Podesivo
[Ir] long-time protection pick-up adjustment range	0.7...1 x In
Long-time protection delay adjustment type tr	Fiksno
[tr] long-time protection delay adjustment range	120...400 Sekundi pri 1.5 x In 15 sekundi pri 6 x Ir
Short-time protection pick-up adjustment type Isd	Fiksno
[Isd] Short-time protection pick-up adjustment range	800 A
Short-time protection delay adjustment type tsd	Fiksno
Diferencijalna zaštita	Bez

Okruženje

Standardi	UL 508 EN/IEC 60947-2
Sertifikacija proizvoda	EAC CCC Marine
Temperatura okoline za rad uređaja	-25...70 °C
Temperatura okoline za skladištenje	-50...85 °C

Informacije navedene u ovoj dokumentaciji predstavljaju opšti opis odnosno tehničke karakteristike performansi proizvoda. Dokumentacija nije namenjena da bude zamena za niti se može koristiti za određivanje prikladnosti i pouzdanosti proizvoda za specifičnu krajnju primenu. Dužnost je korisnika odnosno integratora da izvrši primerenu i sveobuhvatnu analizu rizika, procenu i proveru proizvoda u pogledu odgovarajuće specifične primene ili načina korišćenja. Ni Schneider Electric Industries SAS ni njegova povezana ili zavisna društva neće snositi odgovornost za zloupotrebu ovdeneđenih informacija.

Pakovanje

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	6,500 cm
Package 1 Width	9,500 cm
Package 1 Length	11,500 cm
Package 1 Weight	389,000 g
Unit Type of Package 2	S03
Number of Units in Package 2	28
Package 2 Height	30,000 cm
Package 2 Width	30,000 cm
Package 2 Length	40,000 cm
Package 2 Weight	11,295 kg
Unit Type of Package 3	P12
Number of Units in Package 3	224
Package 3 Height	45,000 cm
Package 3 Width	80,000 cm
Package 3 Length	120,000 cm
Package 3 Weight	102,360 kg

Održivost ponude

Status održive ponude	Green Premium proizvod
Propis REACH	REACH Deklaracija
EU RoHS direktiva	Usaglašeno EU RoHS Deklaracija
Bez žive	Da
RoHS regulativa za Kinu	RoHS Deklaracija Za Kinu
Informacije o RoHS izuzecima	Da
Izjava o zaštiti okoliša	Profil Ekološke Prihvatljivosti Proizvoda
Profil cirkularnosti	Informacije O Kraju Radnog Veka
WEEE	Ovaj proizvod je na tržištima Evropske unije neophodno odložiti u skladu sa specifičnim smernicama za prikupljanje otpada i nikako ne sme da dospe u kontejnere za otpatke.

Ugovorna garancija

Garancija	18 months
-----------	-----------