


Tehničke karakteristike proizvoda

Karakteristike

NU173430

Ugradna kutija 3 kolone aluminijum

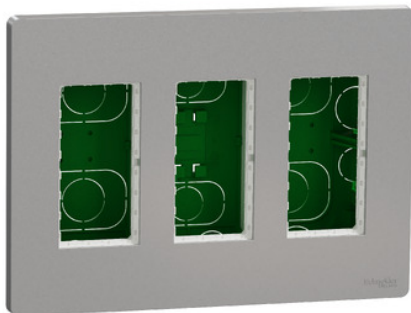

Osnovne informacije

Grupa proizvoda	New Unica
Tip proizvoda ili komponente	Radna stanica
Broj modula	3 x 4 modules
Pozicija montiranja ručice	Vertikalno
Način pričvršćivanja	Embedment Kukicama

Dopunske informacije

Zaštitna oprema	Montažni ram Ram
Montaža uređaja	Ugradno
Kablovski uvod	6 definisani otvori 20 mm for diameter 6 definisani otvori 25 mm for diameter 2 dno cable entries 45 x 25 mm for size 20 mm for diameter 4 dno cable entries 50 x 35 mm for size 25 mm for diameter
Otpornost na vatru	850 °C, vreme gašenja <30 sekundi
Materijal	ABS (akrilonitril-butadien-stiren): separator PC: kutija ABS (akrilonitril-butadien-stiren): dekorativni ram
Dubina	62 mm
Širina	230 mm
Visina	165 mm
Masa proizvoda	0,401 kg
Otpornost na hemijske supstance	Otporan na alkohol (70%) Otporan na alkohol (96%) Otporan na A-mlečnu kiselinu Otporan na razblaženi kvarterni amonijum Otporan na razblaženo izbeljivač Otporan na razblažen amonijak Otporan na vodu sa sapunom Otporan na čistač kristala Otporan na vodonik peroksid 10 zapremina Otporan na heksan

Okruženje

Ik stepen zaštite	IK04
-------------------	------

Pakovanje

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7,9 cm
Package 1 Width	17,8 cm
Package 1 Length	25,0 cm
Package 1 Weight	521,0 g

Unit Type of Package 2	S04
Number of Units in Package 2	14
Package 2 Height	30,0 cm
Package 2 Width	40,0 cm
Package 2 Length	60,0 cm
Package 2 Weight	8,6 kg
Unit Type of Package 3	P06
Number of Units in Package 3	56
Package 3 Height	80,0 cm
Package 3 Width	80,0 cm
Package 3 Length	60,0 cm
Package 3 Weight	39,676 kg

Održivost ponude

Status održive ponude	Green Premium proizvod
Propis REACH	 REACH Deklaracija
EU RoHS direktiva	Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)  EU RoHS deklaracija
Bez toksičnih teških metala	Da
Bez žive	Da
RoHS regulativa za Kinu	 RoHS Deklaracija Za Kinu
Informacije o RoHS izuzecima	 Da
Izjava o zaštiti okoliša	 Profil Ekološke Prihvatljivosti Proizvoda
Profil cirkularnosti	Nema potrebe za namenskim operacijama recikliranja
Minimum percentage of recycled plastic content	22