


Tehničke karakteristike proizvoda

Karakteristike

NU280451M

Ram Unica Studio 2E tamni alumin./antr

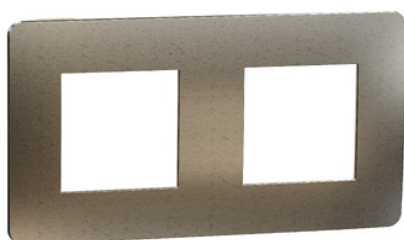

Osnovne informacije

| | |
|------------------------------|-------------------------|
| Grupa proizvoda | New Unica |
| Primena uređaja | Montaža |
| Tip proizvoda ili komponente | Dekorativni ram |
| Ime dekorativnog elementa | Unica Studio Metal |
| Broj dvostrukih modula | Dvostruki |
| Pravac instalacije | Horizontalno vertikalno |
| Tip prekidača | Double |
| Broj modula | 2 x 2 modula |
| Način pričvršćivanja | Zavrtnjima |
| Nijansa boje | Bronzana |
| Side color | Beige (RAL 1013) |

Dopunske informacije

| | |
|---------------------------------|--|
| Materijal | Polikarbonat: međuploča |
| Završna obrada | Brušena završna obrada |
| Količina po setu | Set od 3 |
| Standardi | IEC 60669-1 IEC 60884-1 |
| Širina | 156 mm |
| Visina | 85 mm |
| Dubina | 10 mm |
| Masa proizvoda | 0,033 kg |
| Otpornost na hemijske supstance | Otporan na alkohol (70%) Otporan na alkohol (96%) Otporan na A-mlečnu kiselinu Otporan na razblaženi kvarterni amonijum Otporan na razblaženo izbeljivač Otporan na razblažen amonijak Otporan na vodu sa sapunom Otporan na čistač kristala Otporan na vodonik peroksid 10 zapremina Otporan na heksan |

Okruženje

| | |
|-------------------|--------|
| Ik stepen zaštite | IK04 |
| Ip stepen zaštite | IP21 D |

Pakovanje

| | |
|------------------------------|-----------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Height | 1,000 cm |
| Package 1 Width | 8,500 cm |
| Package 1 Length | 15,500 cm |
| Package 1 Weight | 35,000 g |
| Unit Type of Package 2 | BB1 |

| | |
|------------------------------|-----------|
| Number of Units in Package 2 | 3 |
| Package 2 Height | 6,500 cm |
| Package 2 Width | 12,300 cm |
| Package 2 Length | 18,500 cm |
| Package 2 Weight | 163,000 g |
| Unit Type of Package 3 | S03 |
| Number of Units in Package 3 | 48 |
| Package 3 Height | 30,000 cm |
| Package 3 Width | 30,000 cm |
| Package 3 Length | 40,000 cm |
| Package 3 Weight | 2,988 kg |

Održivost ponude

| | |
|------------------------------|--|
| Status održive ponude | Green Premium proizvod |
| Propis REACh | REACh Deklaracija |
| REACh bez SVHC | Da |
| EU RoHS direktiva | Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS) EU RoHS deklaracija |
| Bez toksičnih teških metala | Da |
| Bez žive | Da |
| Sustainable packaging | Yes |
| RoHS regulativa za Kinu | RoHS Deklaracija Za Kinu |
| Informacije o RoHS izuzecima | Da |
| Izjava o zaštiti okoliša | Profil Ekološke Prihvatljivosti Proizvoda |
| Profil cirkularnosti | Nema potrebe za namenskim operacijama recikliranja |