

Tehničke karakteristike proizvoda

Karakteristike

XS4P12PA340D

induktivni senzor XS4 M12 - D48mm - PPS -
Sn4mm - 12..24VDC - M12



Osnovne informacije

Grupa proizvoda	Telemecanique induktivni senzori blizine XS
Ime serije	Opšta upotreba
Tip senzora	Induktivno blizinski senzor
Ime senzora	XS4
Dizajn senzora	Cilindrični M12
Veličina	48 mm
Tip kućišta	Fiksno
Odobrenje za ugradnu montažu	Neoklopljen
Materijal	Plastika
Tip izlaznog signala	Digitalni
Tehnika ožičenja	3-žični
[sn] nazivna osetljivost	4 mm
Funkcija digitalnog izlaza	1 NO
Tip izlaznog kola	DC
Tip digitalnog izlaza	PNP
Električna veza	Muški konektor M12, 4 pina
[us] nazivni napon napajanja	12...24 V DC sa zaštitom od promene polariteta
Preklopna moć u ma	<= 200 mA DC sa zaštitom od preopterećenja i kratkog spoja
Ip stepen zaštite	IP67 u skladu sa IEC 60529

Dopunske informacije

Tip navoja	M12 x 1
Način detekcije	Čeono
Materijal prednje strane	PPS
Materijal kućišta	PPS
Zona operacije	0...3,2 mm
Razlika puta	1...15% od Sr
Statusne led lampice	Izlazno stanje: 1 LED (žuta)
Granice napona	10...36 V DC
Prekidačka frekvencija	<= 5000 Hz
Maksimalni pad napona	<2 V (zatvoren)
Potrošnja struje	<= 10 mA bez opterećenja
Maksimalno kašnjenje prvog uključanja	10 milisekundi
Maksimalno kašnjenje odgovora	0,1 milisekundi
Maksimalno kašnjenje oporavka	0,1 milisekundi
Označavanje	CE
Dužina navoja	27 mm
Visina	18 mm
Dužina	48 mm
Masa proizvoda	0,02 kg

Okruženje

Sertifikacija proizvoda	UL[RETURN]CSA
Temperatura okoline za rad uređaja	-25...70 °C
Temperatura okoline za skladištenje	-40...85 °C
Otpornost na vibracije	25 gn amplituda = +/- 2 mm (f = 10...55 Hz) u skladu sa IEC 60068-2-6
Otpornost na udare	50 gn za 11 milisekundi u skladu sa IEC 60068-2-27

Pakovanje

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3,200 cm
Package 1 Width	5,700 cm
Package 1 Length	8,200 cm
Package 1 Weight	14,000 g
Unit Type of Package 2	S01
Number of Units in Package 2	22
Package 2 Height	15 cm
Package 2 Width	15 cm
Package 2 Length	40 cm
Package 2 Weight	503,000 g


Održivost ponude

Status održive ponude	Green Premium proizvod
Propis REACH	 REACH Deklaracija
EU RoHS direktiva	Proaktivna usaglašenost (proizvod nije u zakonskom okviru direktive EU RoHS)
Bez žive	Da
Informacije o RoHS izuzecima	 Da
Profil cirkularnosti	 Informacije O Kraju Radnog Veka

Ugovorna garancija


Garancija	18 meseci
-----------	-----------

Dimensions

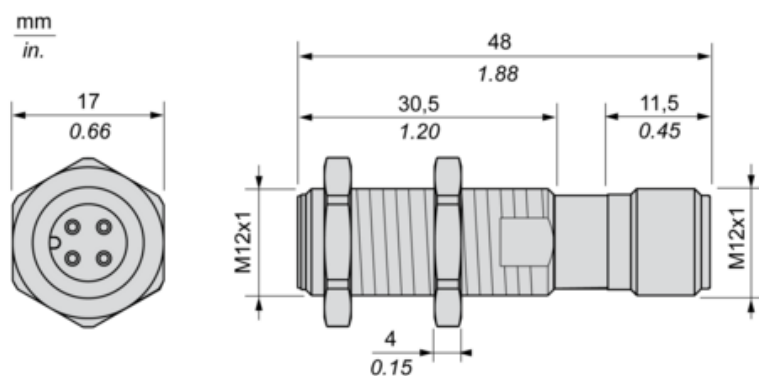


Minimum Mounting Distances

Side by side

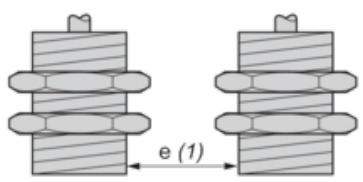


$$e (1) \geq 16 \text{ mm}/0.63 \text{ in.}$$

Face to face

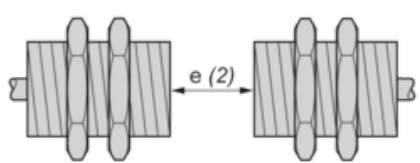


$$e (2) \geq 48 \text{ mm}/1.89 \text{ in.}$$

Facing a metal object

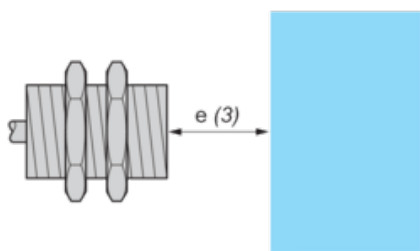

$$e (3) \geq 12 \text{ mm}/0.47 \text{ in.}$$

Mounted in a metal support

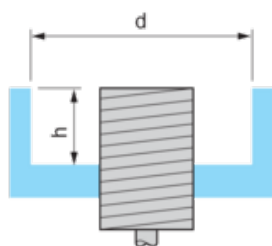


$$d \geq 36 \text{ mm}/1.42 \text{ in.}$$


$$h \geq 8 \text{ mm}/0.31 \text{ in.}$$

Wiring Schemes

M12 connector

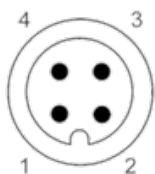


PNP

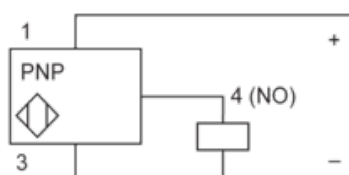

- 1 : (+)
- 2 : Not connected
- 3 : (-)
- 4 : NO Output

Performance Curves

Standard Steel Target : 12x12x1 mm

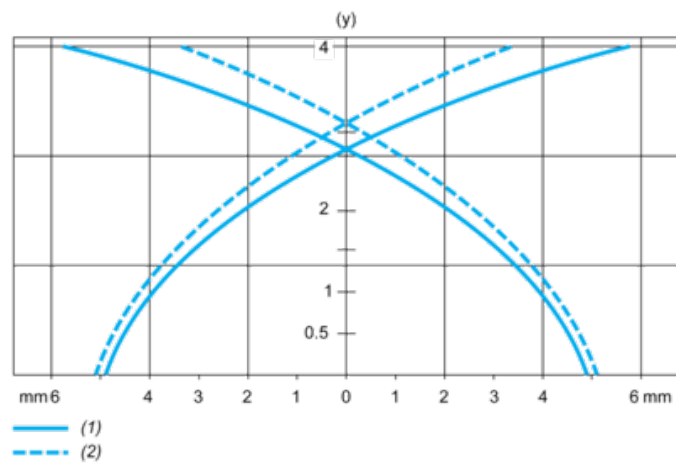

(1) Pick-up points

(2) Drop-out points (object approaching from the side)

(y) Sensing distance in mm