



Produktdata

Produktområde	Harmony XVU
Typ av produkt eller komponent	Modulär ljuspelare
Typ av ljuspelare	LED-enhet
Montagediameter	60 mm
Komponentnamn	XVU
Ljuskälla	LED, blå
Enhetsapplikation	Verktygsmaskiner Fordonsindustri Förpackningsmaskin

Teknisk data

Signaltyp	Blinkande
Monterings sätt	Kundanpassning, upp till 5 enheter Upp till 4 enheter med ljudenhet
Material	PC (polykarbonat) V-2 flamskyddad överensstämmer med UL 94 PC (polykarbonat) V-0 flamskyddad överensstämmer med UL 94
[Us] matningsspänning	24 V AC/DC
Maximal effektförlust i W	1,2 W
Typ av signal	Blinkande
Längd	50 mm
Produktens vikt	0,064 kg

Miljö

Produktcertifieringar	CSA[RETURN]UL[RETURN]CE
Omgivande lufttemperatur för lagring	-40...70 °C
IP-kapslingsklass	IP65
Omgivningstemperatur vid drift	-25...50 °C
Vibrationsbeständighet	2 gn

Förpackningsinformation

Förpackningstyp 1	PCE
Antal i Förpackning 1	1
Förpackning 1 höjd	9,0 cm
Förpackning 1 bredd	9,1 cm
Förpackning 1 djup	13,3 cm
Förpackning 1 vikt	143,0 g
Förpackningstyp 2	S03
Antal i Förpackning 2	24
Förpackning 2 höjd	30 cm
Förpackning 2 bredd	30 cm
Förpackning 2 djup	40 cm
Förpackning 2 vikt	4,061 kg
Förpackningstyp 3	P06
Number of Units in Package 3	192

Förpackning 3 höjd	75 cm
Förpackning 3 bredd	40 cm
Förpackning 3 djup	80 cm
Förpackning 3 vikt	52,456 kg

Hållbarhetsinformation

Hållbarhetsstatus	Green Premium-produkt
REACH-förordning	REACH-Deklaration
EU RoHS-direktiv	Proaktiv överensstämmelse (produkten utanför EU RoHS juridiska omfattning)
Kvicksilverfri	Ja
RoHS-förordning Kina	RoHS-deklaration Kina
RoHS-undantagsinformation	Ja
Miljöupplysning	Produktmiljöprofil
Cirkulationsprofil	Information Om Livslängdsslut


Logistik information

Ursprungsland	ID
---------------	----


Illuminated LED Unit

Dimensions

$\frac{\text{mm}}{\text{in.}}$

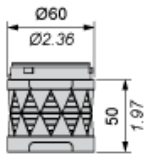


Modular Tower Lights Mounting

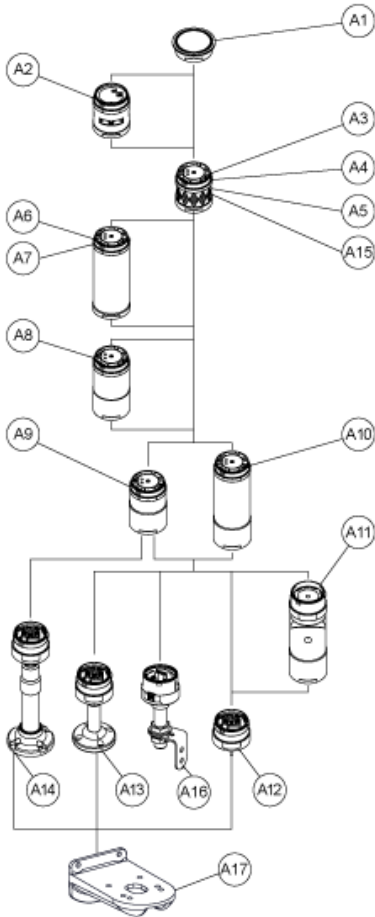

Drawing	Part number	Part name
A1	-	Top cover
-	Top cover (Silver)	
A2	XVUC9S	Buzzer unit
XVUC9SQ	Buzzer unit (Silver)	
A3	XVUC23	Green LED unit
XVUC24	Red LED unit	
XVUC25	Orange LED unit	
XVUC26	Blue LED unit	
XVUC27	White LED unit	
XVUC28	Yellow LED unit	
A4	XVUC29	Multi-LED unit
A5	XVUC29P	Multi-LED unit, Pulse signal
A6	XVUC9V	Sound unit
A7	XVUC9VP	Sound unit, Pulse signal
A8	XVUC020	Extender
XVUC020Q	Extender (Silver)	
A9	XVUC21B	DC body

Drawing	Part number	Part name
XVUC21BQ	DC body (Silver)	
A10	XVUC21M	AC body NPN
XVUC21MP	AC body PNP	
XVUC21MQP	AC body PNP (Silver)	
A11	XVUZ06	Flexible option
A12	XVUZ01	Fixing Unit - Direct mounting (3 pins)
XVUZ01Q	Fixing Unit - Direct mounting (Silver,3 pins)	
XVUZ03	Fixing Unit - Direct mounting (2 pins)	
XVUZ04	Fixing Unit - Direct mounting (4 pins)	
A13	XVUZ02	Fixing Unit - Plate with Pole (100 mm)
XVUZ02Q	Fixing Unit - Plate with Pole (100 mm, Silver)	
XVUZ400	Fixing Unit - Plate with Pole (400 mm)	
XVUZ800	Fixing Unit - Plate with Pole (800 mm)	
A14	XVUZ05	Fixing Unit - Plate with adjustment pole (100-385 mm)
A15	XVUC43	Green LED unit, Flash
XVUC44	Red LED unit, Flash	
XVUC45	Orange LED unit, Flash	
XVUC46	Blue LED unit, Flash	
XVUC47	White LED unit, Flash	
XVUC48	Yellow LED unit, Flash	
A16	XVUZ100T	Fixing Unit - Metal bracket with pole (100 mm)
XVUZ250T	Fixing Unit - Metal bracket with pole(250 mm)	
XVUZ400T	Fixing Unit - Metal bracket with pole (400 mm)	
A17	XVUZ12	Fixing plate for use on vertical support - black

Illuminated Units, Multi-LED and Audible Units Wiring

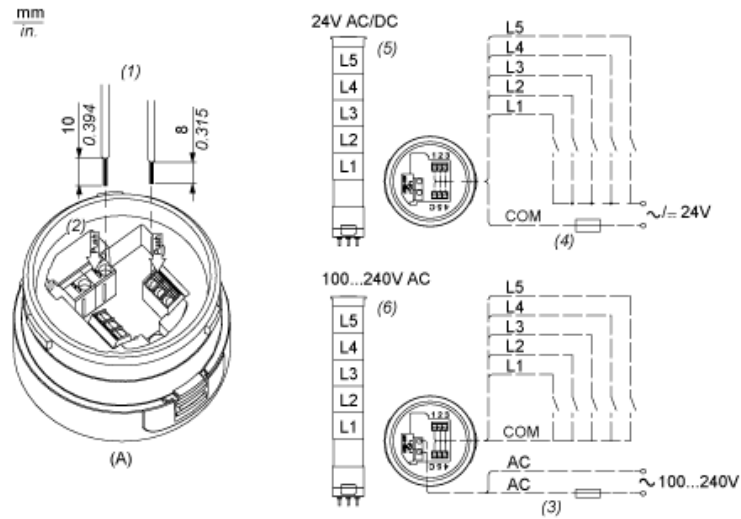

- (A) Fixing Unit
 - (1) Dimensions of Wiring size
 - (2) Push-in Wire Connectors
 - (3) Fuse : 2A ,250V
 - (4) Fuse : 0.5A ,125V
 - (5) Modular Tower Lights 24V AC/DC
 - (6) Modular Tower Lights 100...240V AC
- L1 to Illuminated LED Units
L5 :