


Product data sheet

Characteristics

10205

Micro Pragma nadom. omara - IP30 - 1 x 2 modula - obojestr. prosojna vrata

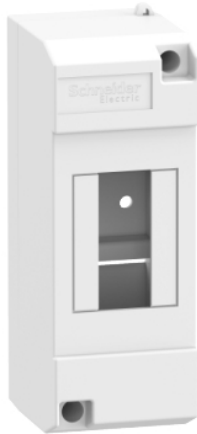

Predstavitev

Skupina izdelkov	Micro Pragma
Izdelek ali sestavni del	Omara
Tip omare	Modularna omara
Nb of 18 mm modules per row	2
Nb of horizontal rows	1
Type of door	Reverzibilen Prozorna
Širina	51 mm
Višina	130 mm
Globina	60 mm
Built-in depth	0 mm

Komplementarno

Montaža omare	Nadometna
9 mm rastri	4
Skupno število 18 mm modulov	2
Tip letve	DIN
Opis montažne plošče	Brez montažne plošče
Material omare	Omara Samougasljivi material
Notranja globina	54 mm
Barva	Omara Bela RAL 9003)
Tržni segment	Majhno komercialno

Okolje

Standardi	EN 60439-3 IEC 60439-3 IEC 60695-2-1 IEC 23-48
Požarna odpornost	650 °C 30 s) IEC 60695-2-1
IP stopnja zaščite	IP40 IEC 60529 with installation of devices IP40 minimum)
IK stopnja zaščite	IK07 EN 50102

Embalažna enota

Teža embalaže 1	75 g
Teža embalaže 2	3,875 kg
Teža embalaže 3	74 kg

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Trajnost ponudbe

Status trajnostne ponudbe	Izdelek Green Premium
Uredba REACH	Izjava REACH
Direktiva EU ROHS	Proaktivno zagotavljanje skladnosti (izdelek je zunaj področja uporabe direktive EU RoHS) Izjava EU RoHS
Brez živega srebra	Da
Informacije o izvzetju iz RoHS	Da
Uredba o RoHS za Kitajsko	Izjava O RoHS Za Kitajsko
Razkritje okoljskih podatkov	Okoljski Profil Izdelka

Pogodbena garancija

Garancija	18 months
-----------	-----------