


Product data sheet

Characteristics

ZC2JE09

Limit switch head, Limit switches XC Standard, ZC2J, without lever stay put left and right actuation

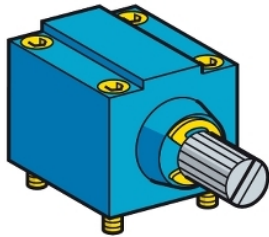

Main

Range of product	OsiSense XC
Series name	Special format
Product or component type	Limit switch head
Device short name	ZC2J
Head type	Rotary head
Product compatibility	XC2J
Associated lever	ZC2JY61 ZC2JY71
Associated body	ZC2JD2 ZC2JC2 ZC2JD1 ZC2JC1 ZC2JC28 ZC2JC18
Movement of operating head	Rotary
Type of operator	Stay put without operating lever stay put
Type of approach	Lateral approach, 2 directions

Complementary

Switch actuation	From left and right CW and CCW
Positive opening	Without
Net weight	0.21 kg
Head material	Metal

Environment



Ambient air temperature for operation	-25...70 °C
Ambient air temperature for storage	-40...70 °C
Environmental characteristic	Standard environment

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.800 cm
Package 1 Width	5.000 cm
Package 1 Length	9.500 cm
Package 1 Weight	218.000 g
Unit Type of Package 2	S01
Number of Units in Package 2	14
Package 2 Height	15.000 cm
Package 2 Width	15.000 cm

Package 2 Length	40.000 cm
Package 2 Weight	3.233 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
RoHS exemption information	 Yes
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 months
----------	-----------