


Product data sheet

Characteristics

8502SFO1V06

NEMA Contactor, Type S, nonreversing, Size 4, 135A, 1 phase, up to 100kA, 2 pole, 480VAC coil, open

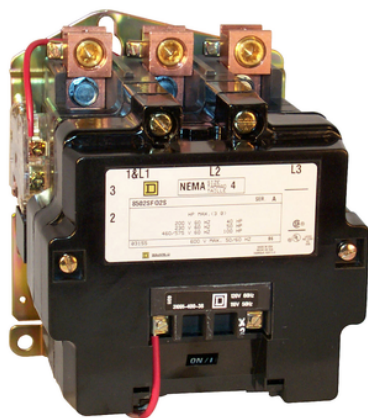

Main

Product Type	Contactors
Product Range	8502S
Contactor Type	Non-reversing

Complementary

NEMA Size	4
Rated Current	135 A
Number of Poles	2P
Maximum Voltage Rating	600 V AC
Phase	1 phase
Horsepower Rating	Not rated
SCCR	Circuit-breaker 225 A maximum, SCCR: 100 kA at 480 V AC Fuse J 200 A maximum, SCCR: 100 kA at 600 V AC Fuse T 200 A maximum, SCCR: 100 kA at 600 V AC Fuse RK1 200 A maximum, SCCR: 100 kA at 600 V AC Fuse RK5 200 A maximum, SCCR: 100 kA at 600 V AC
Coil Voltage	480 V AC 60 Hz 440 V AC 50 Hz
Control Circuit Type	Common control circuit
Control Units	No control units
Pilot Light	No indicator
Auxiliary Contacts	Without
Other Equipment	Fuse not supplied
Terminal Type	Screw clamp terminals
Height	8.19 in (208.03 mm)
Width	6.00 in (152.40 mm)
Depth	6.50 in (165.10 mm)

Environmental

Enclosure Type	Not rated (open device)
Certifications	UL listed file E78351 CCN NLDX[RETURN]CSA

Ordering and shipping details

Category	US10CP121193
Discount Schedule	OCP1
GTIN	785901831532
Returnability	No
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.70 in (19.558 cm)
Package 1 Width	8.80 in (22.352 cm)
Package 1 Length	14.40 in (36.576 cm)
Package 1 Weight	17.05 lb(US) (7.734 kg)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Not compliant
China RoHS Regulation	China RoHS Declaration

Contractual warranty

Warranty	18 months
----------	-----------