


Product data sheet

Characteristics

8903SPO3V02

Contactor, Type S, multipole lighting,
electrically held, 60A, 4 pole, 110/120VAC
50/60Hz coil, open style

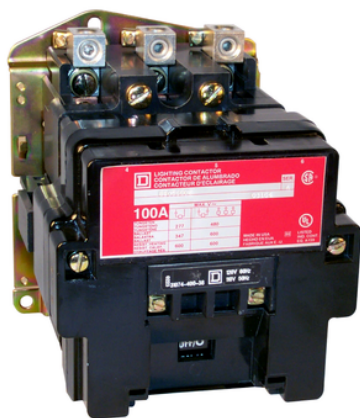

Main

Product	Electrically Held Lighting Contactor
Type	S

Complementary

Control Circuit Voltage	120 V AC 60 Hz 110 V AC 50 Hz
Current Rating	60 A
Number of Poles	4P
Control Units	No control units
Pilot Light	Without pilot light
Auxiliary Contacts	Without
Other Options	None
Electrical Connection	Lugs
Height	5.51 in (140 mm)
Depth	4.92 in (125 mm)
Width	5.59 in (142 mm)

Environment

Enclosure Type	Not rated (open device) surface none
Product Certifications	UL Listed[RETURN]CSA

Ordering and shipping details

Category	US10CP121325
Discount Schedule	0CP1
GTIN	785901455417
Returnability	No
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.00 in (17.78 cm)
Package 1 Width	6.40 in (16.256 cm)
Package 1 Length	9.10 in (23.114 cm)
Package 1 Weight	6.92 lb(US) (3.139 kg)

Offer Sustainability

REACH Regulation	 REACH Declaration
EU RoHS Directive	Not compliant
China RoHS Regulation	 China RoHS Declaration

Contractual warranty

Warranty	18 months
----------	-----------