


8903SQQ02V04

Contactor, Type S, multipole lighting,
electrically held, 100A, 3 pole, 277VAC 60Hz
coil, open style

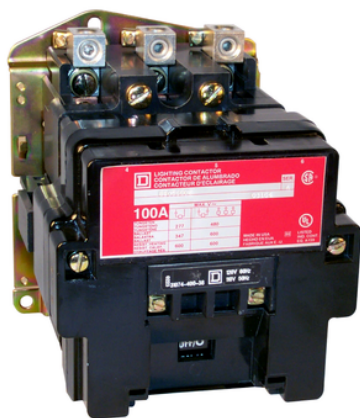

Main

Product	Electrically Held Lighting Contactor
Type	S

Complementary

Control Circuit Voltage	277 V AC 60 Hz
Current Rating	100 A
Number of Poles	3P
Control Units	No control units
Pilot Light	Without pilot light
Auxiliary Contacts	Without
Other Options	None
Electrical Connection	Lugs
Height	7.24 in (184 mm)
Depth	6.50 in (165 mm)
Width	5.43 in (138 mm)

Environment

Enclosure Type	Not rated (open device) surface none
Product Certifications	UL Listed[RETURN]CSA

Ordering and shipping details

Category	US10CP121325
Discount Schedule	OCP1
GTIN	785901159971
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.40 in (18.796 cm)
Package 1 Width	8.80 in (22.352 cm)
Package 1 Length	14.30 in (36.322 cm)
Package 1 Weight	11.78 lb(US) (5.343 kg)

Offer Sustainability

REACH Regulation	 REACH Declaration
EU RoHS Directive	Not compliant
China RoHS Regulation	 China RoHS Declaration

Contractual warranty

Warranty	18 months
----------	-----------