


8903SQQ03V02

Contactor, Type S, multipole lighting,
electrically held, 100A, 4 pole, 120/100VAC
60/50Hz coil, open style

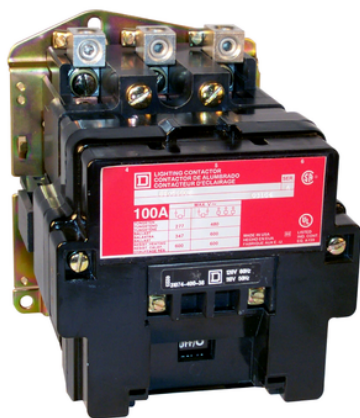

Main

Product	Electrically Held Lighting Contactor
Type	S

Complementary

Control Circuit Voltage	120 V AC 60 Hz 110 V AC 50 Hz
Current Rating	100 A
Number of Poles	4P
Control Units	No control units
Pilot Light	Without pilot light
Auxiliary Contacts	Without
Other Options	None
Electrical Connection	Lugs
Height	7.24 in (184 mm)
Depth	6.50 in (165 mm)
Width	9.76 in (248 mm)

Environment

Enclosure Type	Not rated (open device) surface none
Product Certifications	UL Listed[RETURN]CSA

Ordering and shipping details

Category	US10CP121325
Discount Schedule	0CP1
GTIN	785901861867
Returnability	No
Country of origin	US

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	8.50 in (21.59 cm)
Package 1 Width	11.40 in (28.956 cm)
Package 1 Length	13.60 in (34.544 cm)
Package 1 Weight	21.20 lb(US) (9.616 kg)

Offer Sustainability

REACH Regulation	 REACH Declaration
EU RoHS Directive	Not compliant
China RoHS Regulation	 China RoHS Declaration

Contractual warranty

Warranty	18 months
----------	-----------