


9065SFB20

Overload Relay, Motor Logic, solid state
overload relay, NEMA Size 00, 3 pole, 1.5A to
4.5A, 600VAC, separate mount

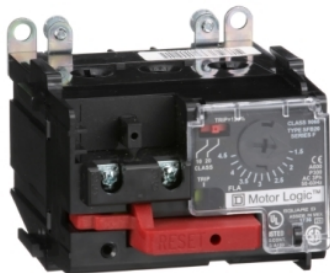

Main

Range of Product	Motor Logic
Thermal overload type	Solid state

Complementary

NEMA size	00
Phase	3 phase
Mounting Support	Mounting plate
[Ue] rated operational voltage	600 V AC
Height	2.69 in (68.3 mm)
Width	3.26 in (82.8 mm)
Depth	3.90 in (99.1 mm)

Ordering and shipping details

Category	US10CP121662
Discount Schedule	0CP1
GTIN	785901039686
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	5.12 in (13.0 cm)
Package 1 Width	5.43 in (13.8 cm)
Package 1 Length	6.02 in (15.3 cm)
Package 1 Weight	15.52 oz (440 g)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
RECh Regulation	RECh Declaration
EU RoHS Directive	Compliant with Exemptions
Mercury free	Yes

China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information
PVC free	Yes
Contractual warranty	
Warranty	18 months