


9422ATCF301

Operating mechanism, flange mounted,
variable depth, 30A, 250V, fuseholder, switch
mechanism, 6 inch handle, NEMA 4

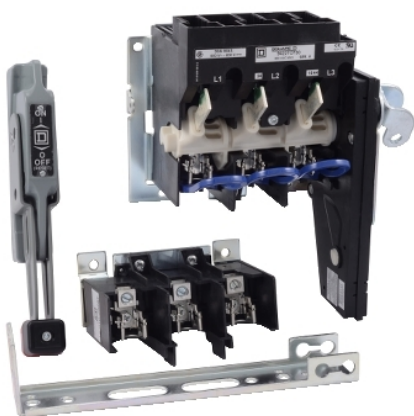

Main

Range	9422T
Product	Disconnect Switch
Disconnect Type	Fusible disconnect switch

Complementary

Mounting Type	Flange rod variable depth
Current Rating	30 A
Horsepower Rating	7.5 Hp 200 V AC 7.5 Hp 230 V AC 15 Hp 460 V AC 20 Hp 575 V AC 5 hp 250 V DC
Fuse Rating	30 A 250 V
Handle Type	6 in handle included NEMA 1/3/3R/4 enclosures sheet steel
Fuse Type	H K J R

Environment

Certifications	UL Recognized[RETURN]CSA
----------------	--------------------------

Ordering and shipping details

Category	US10CP121732
Discount Schedule	OCP1
GTIN	785901872153
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.30 in (18.542 cm)
Package 1 Width	11.30 in (28.702 cm)
Package 1 Length	16.00 in (40.64 cm)
Package 1 Weight	8.80 lb(US) (3.992 kg)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant with Exemptions
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
PVC free	Yes

Contractual warranty

Warranty	18 months
----------	-----------