


9422TDF60

Operating mechanism, flange mounted,
variable depth, 30A, 600V, H, K, J, R
fuseholder, switch mechanism

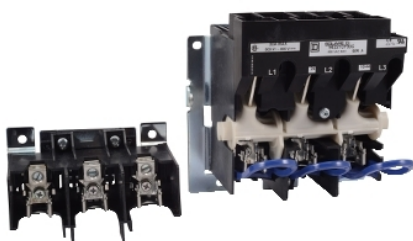

Main

Range	9422T
Product	Disconnect Switch
Disconnect Type	Fusible disconnect switch

Complementary

Mounting Type	Flange rod variable depth
Current Rating	60 A
Horsepower Rating	15 Hp 200 V AC 15 Hp 230 V AC 30 Hp 460 V AC 50 Hp 575 V AC 10 hp 250 V DC
Fuse Rating	60 A 250 V 30 A 600 V
Handle Type	Ordered separately
Fuse Type	R K H J

Environment

Certifications	CSA[RETURN]UL Recognized
----------------	--------------------------

Ordering and shipping details

Category	US10CP121732
Discount Schedule	OCP1
GTIN	785901879794
Returnability	No
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.13 in (18.100 cm)
Package 1 Width	11.10 in (28.200 cm)
Package 1 Length	15.91 in (40.400 cm)
Package 1 Weight	6.18 lb(US) (2.805 kg)
Unit Type of Package 2	P12
Number of Units in Package 2	12
Package 2 Height	35.43 in (90.000 cm)

Package 2 Width	31.50 in (80.000 cm)
Package 2 Length	47.24 in (120.000 cm)
Package 2 Weight	100.66 lb(US) (45.660 kg)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes

Contractual warranty

Warranty	18 months
----------	-----------