


9422TF1

Operating mechanism, flange mounted,
variable depth, 200A, 600V, no fuse, switch
mechanism

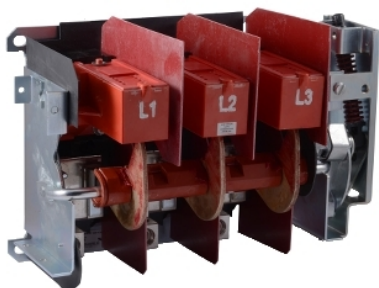

Main

Range	9422T
Product	Disconnect Switch
Disconnect Type	Non-fusible disconnect switch

Complementary

Mounting Type	Flange rod variable depth
Current Rating	200 A
Horsepower Rating	40 Hp 200 V AC 60 Hp 230 V AC 125 Hp 460 V AC 150 Hp 575 V AC 40 hp 250 V DC
Handle Type	Ordered separately

Environment

Certifications	UL Recognized[RETURN]CSA
----------------	--------------------------

Ordering and shipping details

Category	US10CP121732
Discount Schedule	0CP1
GTIN	785901043737
Returnability	No
Country of origin	US

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	9.20 in (23.368 cm)
Package 1 Width	12.10 in (30.734 cm)
Package 1 Length	20.80 in (52.832 cm)
Package 1 Weight	21.18 lb(US) (9.607 kg)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant with Exemptions
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
PVC free	Yes

Contractual warranty

Warranty	18 months
----------	-----------