


Product data sheet

Characteristics

9422TFB2

Operating mechanism, flange mounted, bracket mount, fixed depth assembly, 200A, 600V, H, K, J, R fuseholder, switch mechanism, 6 inch handle

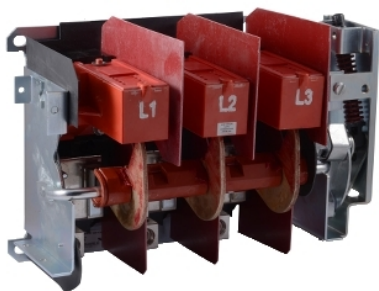

Main

Range	9422T
Product	Disconnect Switch
Disconnect Type	Fusible disconnect switch

Complementary

Mounting Type	Bracket fixed depth
Current Rating	200 A
Horsepower Rating	40 Hp 200 V AC 60 Hp 230 V AC 125 Hp 460 V AC 150 Hp 575 V AC 40 hp 250 V DC
Fuse Rating	200 A 250/600 V
Handle Type	6 in handle included
Fuse Type	K R J H

Environment

Certifications	CSA[RETURN]UL Recognized
----------------	--------------------------


Ordering and shipping details

Category	US10CP121732
Discount Schedule	0CP1
GTIN	785901043782
Returnability	No
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	13.50 in (34.29 cm)
Package 1 Width	14.50 in (36.83 cm)
Package 1 Length	23.00 in (58.42 cm)
Package 1 Weight	28.19 lb(US) (12.788 kg)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	 REACH Declaration
EU RoHS Directive	Compliant with Exemptions
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
PVC free	Yes

Contractual warranty

Warranty	18 months
----------	-----------