


# LXD3P7

Contacteur coil, TeSys Deca, LXD3, 230V AC  
50/60Hz for 40...65A contactor

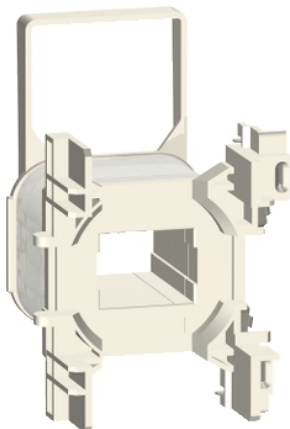

## Main

Range	TeSys
Product or Component Type	Contacteur coil
Device short name	LXD3
Control circuit type	AC 50/60 Hz
[Uc] control circuit voltage	230 V AC 50/60 Hz
Average resistance	192 Ohm 68 °F (20 °C)
Inductance of closed circuit	10.9 H
Product Compatibility	LC1DT80A LC1D40A...D65A LC1DT60A
Mechanical durability	6 Mcycles
Maximum operating rate	3600 cyc/h 140 °F (60 °C)

## Complementary

Coil technology	Without built-in suppressor module
Control circuit voltage limits	Drop-out: 0.3...0.6 Uc at 50/60 Hz (at <140 °F (60 °C)) Operational: 0.8...1.1 Uc at 50 Hz (at <140 °F (60 °C)) Operational: 0.85...1.1 Uc at 60 Hz (at <140 °F (60 °C))
Inrush power in VA	160 VA 60 Hz cos phi 0.75 (at 68 °F (20 °C)) 160 VA 50 Hz cos phi 0.75 (at 68 °F (20 °C))
Hold-in power consumption in VA	15 VA 60 Hz cos phi 0.3 (at 68 °F (20 °C)) 15 VA 50 Hz cos phi 0.3 (at 68 °F (20 °C))
Heat dissipation	4...5 W 50/60 Hz

## Environment

Ambient air temperature for operation	23...140 °F (-5...60 °C)
Net Weight	0.15 lb(US) (0.07 kg)

## Ordering and shipping details

Category	US10I1222341
Discount Schedule	0I12
GTIN	3389119410427
Returnability	Yes
Country of origin	US

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.28 in (5.8 cm)
Package 1 Width	2.28 in (5.8 cm)
Package 1 Length	3.86 in (9.8 cm)
Package 1 Weight	4.27 oz (121 g)
Unit Type of Package 2	S02
Number of Units in Package 2	30
Package 2 Height	5.91 in (15 cm)
Package 2 Width	11.81 in (30 cm)

Package 2 Length	15.75 in (40 cm)
Package 2 Weight	9.01 lb(US) (4.085 kg)
Unit Type of Package 3	P06
Number of Units in Package 3	240
Package 3 Height	31.50 in (80 cm)
Package 3 Width	31.50 in (80 cm)
Package 3 Length	23.62 in (60 cm)
Package 3 Weight	111.42 lb(US) (50.54 kg)

### Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Antimony oxide & Antimony trioxide, which is known to the State of California to cause cancer. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
PVC free	Yes

### Contractual warranty

Warranty	18 months
----------	-----------