


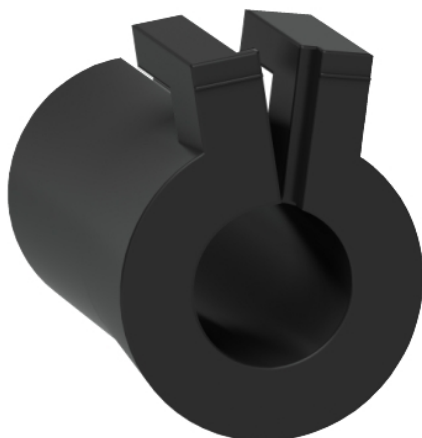

## Main

|                                    |                            |
|------------------------------------|----------------------------|
| Range                              | Spacial                    |
| Product or Component Type          | Grommet                    |
| Accessory / separate part category | Cable management accessory |
| Device Application                 | Multi-purpose              |
| Quantity per Set                   | Set of 12                  |

## Complementary

|                    |                               |
|--------------------|-------------------------------|
| Material           | TPE (thermoplastic elastomer) |
| Cable entry number | 1 x 0.31...0.35 in (8...9 mm) |
| Net Weight         | 0.01 lb(US) (0.004 kg)        |

## Environment

|                                       |                                                                                                                                                  |
|---------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------|
| IP degree of protection               | IP65 conforming to IEC 60529                                                                                                                     |
| Flame retardance                      | V0 conforming to UL 94                                                                                                                           |
| Ambient air temperature for operation | -22...212 °F (-30...100 °C)                                                                                                                      |
| Resistance to chemical agents         | Good resistance to fuels<br>Good resistance to mineral oils and greases<br>Good resistance to weak acids and bases<br>Good resistant to alcohols |

## Packing Units

|                              |                     |
|------------------------------|---------------------|
| Unit Type of Package 1       | PCE                 |
| Number of Units in Package 1 | 1                   |
| Package 1 Height             | 1.18 in (3.0 cm)    |
| Package 1 Width              | 1.48 in (3.75 cm)   |
| Package 1 Length             | 3.54 in (9.0 cm)    |
| Package 1 Weight             | 0.14 oz (4.0 g)     |
| Unit Type of Package 2       | BB1                 |
| Number of Units in Package 2 | 12                  |
| Package 2 Height             | 1.18 in (3.0 cm)    |
| Package 2 Width              | 3.54 in (9.0 cm)    |
| Package 2 Length             | 5.91 in (15.0 cm)   |
| Package 2 Weight             | 1.83 oz (52.0 g)    |
| Unit Type of Package 3       | CAR                 |
| Number of Units in Package 3 | 240                 |
| Package 3 Height             | 7.87 in (20.0 cm)   |
| Package 3 Width              | 7.87 in (20.0 cm)   |
| Package 3 Length             | 11.81 in (30.0 cm)  |
| Package 3 Weight             | 46.98 oz (1332.0 g) |

## Offer Sustainability

|                            |                                                            |
|----------------------------|------------------------------------------------------------|
| Sustainable offer status   | Green Premium product                                      |
| REACH Regulation           | <a href="#">REACH Declaration</a>                          |
| EU RoHS Directive          | Pro-active compliance (Product out of EU RoHS legal scope) |
| Mercury free               | Yes                                                        |
| China RoHS Regulation      | <a href="#">China RoHS Declaration</a>                     |
| RoHS exemption information | <a href="#">Yes</a>                                        |
| Environmental Disclosure   | <a href="#">Product Environmental Profile</a>              |
| Circularity Profile        | No need of specific recycling operations                   |