


NSYPLM3025G

Wall mounted polyester enclosure, Thalassa PLM, plain door, 308x255x160mm, IP66, IK10, RAL 7035

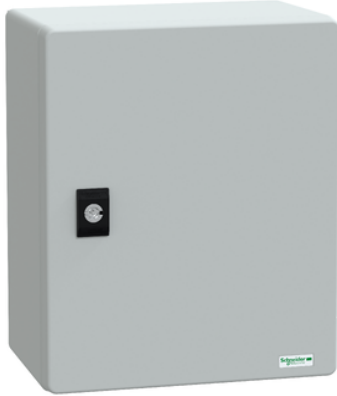

Main

Range	Thalassa
Product name	Thalassa PLM
Device short name	PLM
Enclosure type	Multi-purpose
Category	Compact enclosure
Nominal height	12.13 in (308 mm)
Nominal width	10.04 in (255 mm)
Nominal depth	6.30 in (160 mm)
Enclosure mounting	Wall mounted
Device composition	1 body 1 door 1 lock
Door type	Solid
Lock type	3 mm double-bar lock

Complementary

Number of locks	1
Mounting plate description	Without mounting plate
Accessibility for operation	Front
Removable parts	Door by hinges
Material	Polyester reinforced with fibreglass
Color	Gray RAL 7035)
Standards	IEC 62208 NEMA classification 13 NEMA classification 4X
Product Certifications	UL
Electrical Insulation Class	Class II

Environment

IP degree of protection	IP66 IEC 60529
IK degree of protection	IK10 IEC 62262
Fire resistance	1760 °F (960 °C) IEC 62208
Ambient air temperature for operation	-40...176 °F (-40...80 °C)

Ordering and shipping details

Category	US10ES180034
Discount Schedule	0ES1
GTIN	3606480776434
Returnability	Yes
Country of origin	ES

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.28 in (18.500 cm)
Package 1 Width	10.43 in (26.500 cm)
Package 1 Length	12.80 in (32.500 cm)
Package 1 Weight	7.53 lb(US) (3.414 kg)
Unit Type of Package 2	PAM
Number of Units in Package 2	90
Package 2 Height	59.06 in (150.000 cm)
Package 2 Width	39.37 in (100.000 cm)
Package 2 Length	47.24 in (120.000 cm)
Package 2 Weight	770.54 lb(US) (349.510 kg)

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations