



Main

| | |
|----------------------|------------------|
| Marketing Trade Name | QO |
| Product | Load Center |
| Cover type | Order separately |

Complementary

| | |
|--|--|
| Tightening torque | Main lugs 250 lb.in, AWG 4...250 kcmil, aluminium/copper Cover 20 lb.in |
| Load Center Type | Main lugs |
| Line Rated Current | 200 A |
| Number of spaces | 30 |
| Short Circuit Current Rating | 65 kA |
| Maximum Number of Single Pole Circuits | 30 |
| Maximum Number of Tandem Breakers | 0 |
| Number of Phases | 3 phase |
| Voltage Rating | 208Y/120 V AC 240/120 V delta AC 240 V delta AC |
| Wire Size | AWG 6...250 kcmil aluminium/copper |
| Electrical Connection | Lugs |
| Grounding Bar | Grounding bar included (not installed) |
| Electrical connection | Lugs |
| Wiring configuration | 3-wire 4-wire |
| Busbar Material | Tin plated copper busbar |
| Enclosure Material | Welded sheet steel |
| Cover Finish | Baked enamel Gray |
| Box number | 9 |
| Maximum Height | 29.84 in (758 mm) |
| Width | 14.25 in (362 mm) |

Environment

| | |
|---------------------------------------|---------------------------------|
| Enclosure Rating | NEMA 1 indoor |
| Ambient air temperature for operation | 23 °F (-5 °C) 104 °F (40 °C) |
| Product certifications | UL Listed |

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Ordering and shipping details

| | |
|-----------------------|-----------------------------------|
| Category | 00011 - QO 3PH LOAD CENTER,INDOOR |
| Discount Schedule | DE3 |
| GTIN | 00785901295501 |
| Nbr. of units in pkg. | 1 |
| Package weight(Lbs) | 17.45 lb(US) (7.92 kg) |
| Returnability | Yes |
| Country of origin | US |

Packing Units

| | |
|------------------------------|----------------------------|
| Unit Type of Package 1 | PCE |
| Package 1 Height | 31.00 in (78.74 cm) |
| Package 1 width | 4.20 in (10.668 cm) |
| Package 1 Length | 14.60 in (37.084 cm) |
| Unit Type of Package 2 | PAL |
| Number of Units in Package 2 | 27 |
| Package 2 Weight | 477.00 lb(US) (216.363 kg) |
| Package 2 Height | 42.00 in (106.68 cm) |
| Package 2 width | 40.00 in (101.6 cm) |
| Package 2 Length | 48.00 in (121.92 cm) |


Offer Sustainability

| | |
|----------------------------|---|
| REACH free of SVHC | Yes |
| EU RoHS Directive | Compliant EU RoHS Declaration |
| Toxic heavy metal free | Yes |
| Mercury free | Yes |
| RoHS exemption information | Yes |
| China RoHS Regulation | China RoHS Declaration |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Approximate Dimensions

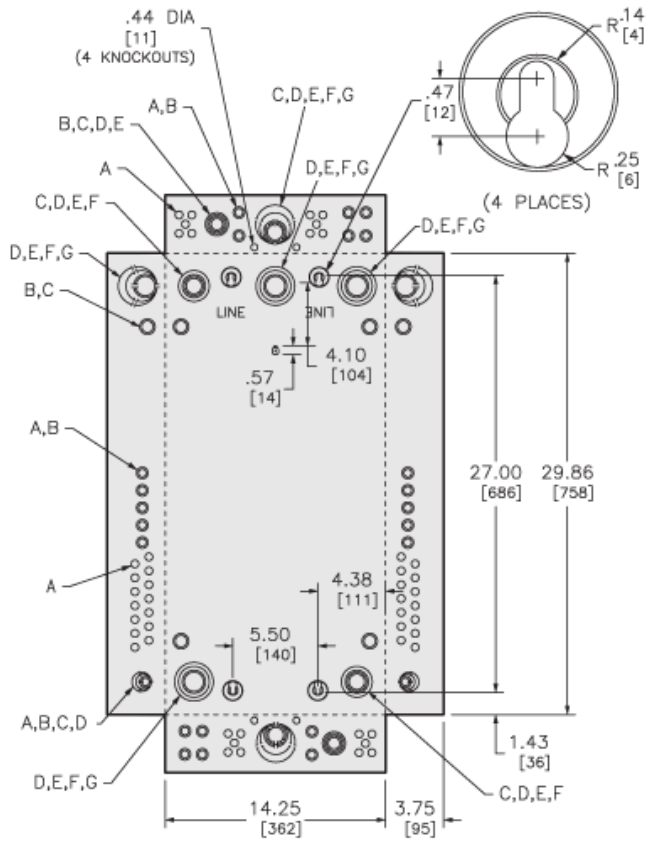

| in. [mm] | KNOCKOUTS | |
|-------------|-----------|--------------|
| | SYMBOL | CONDUIT SIZE |
| | | IN MM |
| | A | .50 13 |
| | B | .75 19 |
| | C | 1.00 25 |
| | D | 1.25 32 |
| | E | 1.50 38 |
| | F | 2.00 51 |
| | G | 2.50 64 |

Connections and Wiring Diagrams

