



Main

Range	Linergy
Product name	FT
Device short name	GV2G
Product or Component Type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys Deca TeSys GV2 TeSys K TeSys U
Number of tap-offs	3
[I _{th}] conventional free air thermal current	63 A
Connection pitch	2.13 in (54 mm)

Complementary

Mounting Location	On terminal
[Ui] Rated Insulation Voltage	690 V
Length	5.98 in (152 mm)
Net Weight	0.13 lb(US) (0.06 kg)

Ordering and shipping details

Category	22367-MANUAL STR PROTECTOR - GV2
Discount Schedule	I11
GTIN	3389110555912
Returnability	Yes
Country of origin	RO

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	0.39 in (1 cm)
Package 1 Width	1.22 in (3.1 cm)
Package 1 Length	5.94 in (15.1 cm)
Package 1 Weight	2.26 oz (64 g)
Unit Type of Package 2	S01
Number of Units in Package 2	70
Package 2 Height	5.91 in (15 cm)
Package 2 Width	5.91 in (15 cm)
Package 2 Length	15.75 in (40 cm)
Package 2 Weight	10.12 lb(US) (4.589 kg)
Unit Type of Package 3	P06
Number of Units in Package 3	2240
Package 3 Height	30.31 in (77 cm)
Package 3 Width	31.50 in (80 cm)

Package 3 Length	23.62 in (60 cm)
Package 3 Weight	350.67 lb(US) (159.06 kg)


Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information

Contractual warranty

Warranty	18 months
----------	-----------

Sets of Busbars GV2G345 and GV2G354

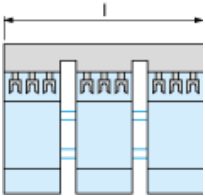

	l
GV2G345 (3 x 45 mm)	134
GV2G354 (3 x 54 mm)	152