

H363N

Safety switch, heavy duty, fusible, 100A, 3 poles, 100 hp, 600 VAC/DC, neutral factory installed, NEMA1



Main

Product	Single Throw Safety Switch
Duty Rating	Heavy duty
Device Application	Heavy application
Disconnect Type	Fusible disconnect
Factory Installed Neutral	Neutral (factory installed)
Phase	3 phase
Number of Poles	3
Current Rating	100 A
Voltage Rating	600 V AC/DC
Enclosure Rating	NEMA 1 steel
Maximum Horse Power Rating	25 Hp 480 V at AC 50-60 Hz for 3 phase conforming to NEC 240.6 60 Hp 480 V at AC 50-60 Hz for 3 phase conforming to NEC 430.52 30 Hp 600 V at AC 50-60 Hz for 3 phase conforming to NEC 240.6 100 Hp 600 V at AC 50-60 Hz for 3 phase conforming to NEC 430.52 50 hp 600 V at DC

Complementary

Short Circuit Current Rating	10 KA H or K 200 kA R or J
Fuse type	H or K R or J
Mounting Type	Surface
Electrical Connection	Lugs
Wiring configuration	4-wire (3PH + N)
Wire Size	AWG 12...AWG 1/0 aluminium AWG 14...AWG 1/0 copper
Tightening torque	50 Lbf.In (5.65 N.m) (AWG 1...AWG 3/0) 45 Lbf.In (5.08 N.m) (AWG 6...AWG 4) 40 Lbf.In (4.52 N.m) 0.01 in ² (8.367 mm ²) (AWG 8) 35 Lbf.in (3.95 N.m) 0.00...0.01 in ² (2.06...5.261 mm ²) (AWG 14...AWG 10)
Depth	6.38 in (162.05 mm)
Width	10.25 in (260.35 mm)
Height	21.25 in (539.75 mm)
Net Weight	19.84 lb(US) (9 kg)

Environment

Certifications	UL listed file E2875
----------------	----------------------

Ordering and shipping details

Category	00008 - H&HU SW,2&3P,N1,30-200A
Discount Schedule	DE1
GTIN	785901482277
Nbr. of units in pkg.	1
Package weight(Lbs)	19.84 lb(US) (9 kg)

Returnability	Yes
Country of origin	US

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	7.30 in (18.542 cm)
Package 1 width	10.70 in (27.178 cm)
Package 1 Length	23.40 in (59.436 cm)



Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
PVC free	Yes

Contractual warranty

Warranty	18 months
----------	-----------

Approximate Dimensions

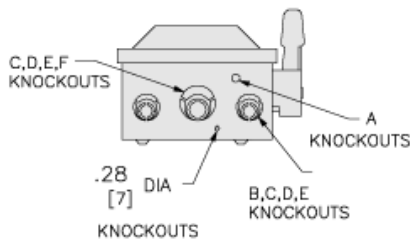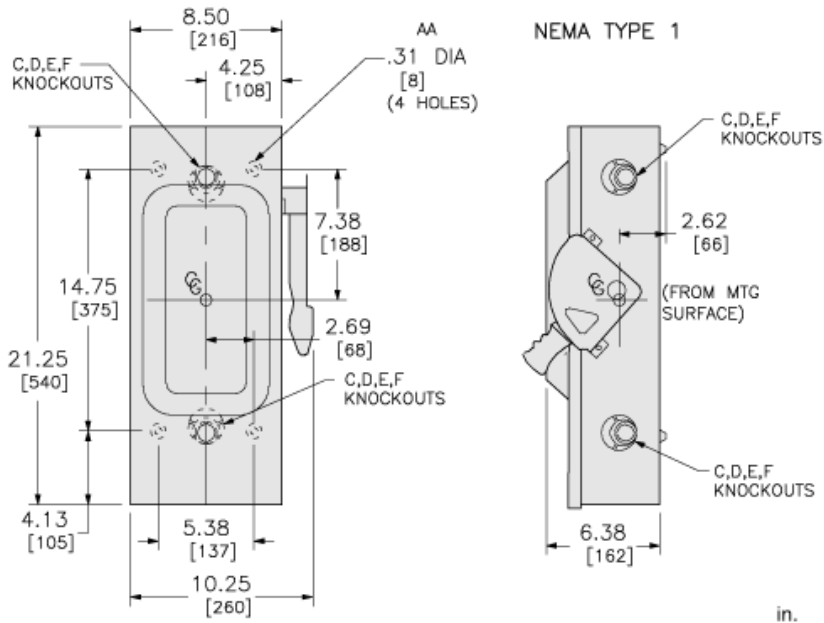

KNOCKOUTS				
SYMBOL	CONDUIT SIZE		DIAMETER	
	IN	MM	IN	MM
A	.50	13	.88	22
B	.75	19	1.13	29
C	1.00	25	1.38	35
D	1.25	32	1.75	45
E	1.50	38	2.00	51
F	2.00	51	2.50	64

in.
[mm]