


LVS03020

Mounting plate, PrismaSeT G, for NSXm/
Vigi/SDx 160A, horizontal fixed, toggle, 3M,
W600mm

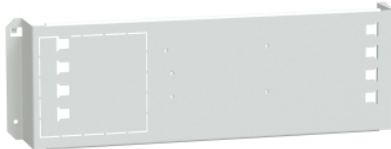

Main

Range	PrismaSeT
Range of product	PrismaSeT G
Product or component type	Mounting plate
Accessory / separate part category	Installation accessory
Range compatibility	PrismaSeT PrismaSeT G enclosure
Installation description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Floor-standing enclosure - width 850 mm Floor-standing enclosure + duct - width 600 + 300 mm Wall-mounted enclosure + duct - width 600 + 300 mm
Mounting plate description	Dedicated
Installed device	ComPact: fixed NSXm without earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSXm with earth leakage protection - control: toggle - horizontal installation
Poles description	1 x 3P or 4P: fixed NSXm horizontal installation
Number of vertical modules [50 mm]	3 module(s): NSXm without earth leakage protection , direct in 600 mm Widefloor-standing enclosure 3 module(s): NSXm without earth leakage protection , direct in 600 mm Widewall-mounted enclosure 3 module(s): NSXm without earth leakage protection , direct in 600 + 300 mm Widefloor-standing enclosure + duct 3 module(s): NSXm without earth leakage protection , direct in 600 + 300 mm Widewall-mounted enclosure + duct 3 module(s): NSXm without earth leakage protection , direct in 850 mm Widefloor-standing enclosure 3 module(s): NSXm with earth leakage protection , direct in 600 mm Widefloor-standing enclosure 3 module(s): NSXm with earth leakage protection , direct in 600 mm Widewall-mounted enclosure 3 module(s): NSXm with earth leakage protection , direct in 600 + 300 mm Widefloor-standing enclosure + duct 3 module(s): NSXm with earth leakage protection , direct in 600 + 300 mm Widewall-mounted enclosure + duct 3 module(s): NSXm with earth leakage protection , direct in 850 mm Widefloor-standing enclosure
Standards	IEC 61439-2
Product certifications	ASTA

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Complementary

Material	Sheet steel
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface finish	Textured Matt
Colour	White (RAL 9003)
Width	470 mm
Height	150 mm
Functional unit	600 mm PrismaSeT G floor-standing enclosure ComPact NSXm without fixed toggle horizontal 3P or 4P 1 direct 3 25 mm 600 mm PrismaSeT G wall-mounted enclosure ComPact NSXm without fixed toggle horizontal 3P or 4P 1 direct 3 25 mm 850 mm PrismaSeT G floor-standing enclosure ComPact NSXm without fixed toggle horizontal 3P or 4P 1 direct 3 25 mm 600 mm PrismaSeT G floor-standing enclosure ComPact NSXm with fixed toggle horizontal 3P or 4P 1 direct 3 25 mm 600 mm PrismaSeT G wall-mounted enclosure ComPact NSXm with fixed toggle horizontal 3P or 4P 1 direct 3 25 mm 850 mm PrismaSeT G floor-standing enclosure ComPact NSXm with fixed toggle horizontal 3P or 4P 1 direct 3 25 mm 600 + 300 mm PrismaSeT G floor-standing enclosure + duct ComPact NSXm without fixed toggle horizontal 3P or 4P 1 direct 3 25 mm 600 + 300 mm PrismaSeT G wall-mounted enclosure + duct ComPact NSXm without fixed toggle horizontal 3P or 4P 1 direct 3 25 mm 600 + 300 mm PrismaSeT G floor-standing enclosure + duct ComPact NSXm with fixed toggle horizontal 3P or 4P 1 direct 3 25 mm 600 + 300 mm PrismaSeT G wall-mounted enclosure + duct ComPact NSXm with fixed toggle horizontal 3P or 4P 1 direct 3 25 mm

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	6 cm
Package 1 Width	14.8 cm
Package 1 Length	47 cm
Package 1 Weight	1.079 kg
Unit Type of Package 2	S04
Number of Units in Package 2	16
Package 2 Height	30 cm
Package 2 Width	40 cm
Package 2 Length	60 cm
Package 2 Weight	18.066 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations
PVC free	Yes
Halogen content performance	Halogen free plastic parts product