


# LVS03031

Mounting plate, PrismaSeT G, for NSX/CVS/  
Vigi 250A, horizontal fixed, rotary handle, 5M,  
W600mm

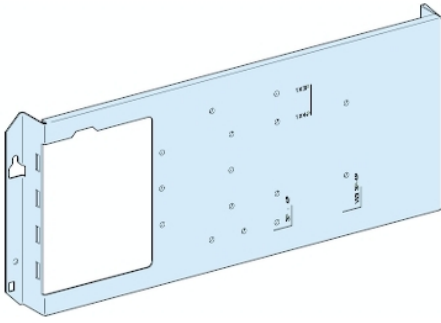



## Main

Range	PrismaSeT
Range of product	PrismaSeT G
Product or component type	Mounting plate
Accessory / separate part category	Installation accessory
Range compatibility	PrismaSeT PrismaSeT G enclosure
Installation description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Floor-standing enclosure - width 850 mm Floor-standing enclosure + duct - width 600 + 300 mm Wall-mounted enclosure + duct - width 600 + 300 mm
Installed device	EasyPact: fixed CVS100...160 without earth leakage protection - control: direct front rotary handle - horizontal installation EasyPact: fixed CVS250 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX250 without earth leakage protection - control: direct front rotary handle - horizontal installation EasyPact: fixed CVS100...160 with earth leakage protection - control: direct front rotary handle - horizontal installation EasyPact: fixed CVS250 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX250 with earth leakage protection - control: direct front rotary handle - horizontal installation
Poles description	1 x 3P: fixed CVS100...160 horizontal installation 1 x 4P: fixed CVS100...160 horizontal installation 1 x 3P: fixed CVS250 horizontal installation 1 x 4P: fixed CVS250 horizontal installation 1 x 3P: fixed NSX100...160 horizontal installation 1 x 4P: fixed NSX100...160 horizontal installation 1 x 3P: fixed NSX250 horizontal installation 1 x 4P: fixed NSX250 horizontal installation
Condition of using cable tie	Need additional plate (2M high) when installation of device is in horizontal





Standards	IEC 61439-2
Product certifications	ASTA

## Complementary

Cable entry	Cut-out plates 0.33 mm top 92 mm Cut-out plates 0.31 mm top 42 mm Cut-out plates 0.31 mm bottom 42 mm
Material	Sheet steel
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface finish	Matt Textured
Colour	White (RAL 9003)
Width	600 mm
Height	150 mm

---

Net weight

1.08 kg

---



## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.2 cm
Package 1 Width	19.2 cm
Package 1 Length	47.0 cm
Package 1 Weight	1.099 kg
Unit Type of Package 2	S04
Number of Units in Package 2	16
Package 2 Height	30.0 cm
Package 2 Width	40.0 cm
Package 2 Length	60.0 cm
Package 2 Weight	18.526 kg

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations
PVC free	Yes
Halogen content performance	Halogen free plastic parts product