


LVS03244

Front plate, PrismaSeT P and G, for Vigi NSX/
CVS250 3P/4P, 7M, vertical, Rotary handle/
motor mechanism/plug-in, white, RAL 9003

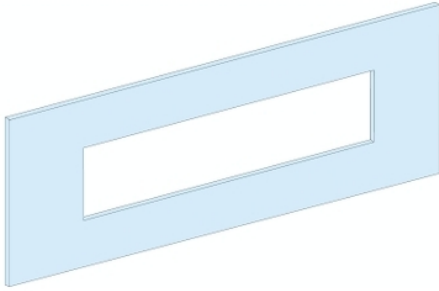



Main

Range	PrismaSeT
Range of product	PrismaSeT G PrismaSeT P
Product or component type	Front plate
Accessory / separate part category	Installation accessory
Range compatibility	PrismaSeT PrismaSeT G enclosure PrismaSeT PrismaSeT P cubicle
Type of front plate	Cut-out
Installed device	<p>EasyPact: fixed CVS100...160 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>EasyPact: fixed CVS250 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: fixed NSX100...160 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: plug-in NSX100...160 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: plug-in NSX100...160 with earth leakage protection - control: motor mechanism - vertical installation</p> <p>ComPact: drawout NSX100...160 with earth leakage protection - control: toggle - vertical installation</p> <p>ComPact: drawout NSX100...160 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: drawout NSX100...160 with earth leakage protection - control: motor mechanism - vertical installation</p> <p>ComPact: fixed NSX100...160 with earth leakage protection - control: motor mechanism - vertical installation</p> <p>ComPact: fixed NSX250 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: plug-in NSX250 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: plug-in NSX250 with earth leakage protection - control: motor mechanism - vertical installation</p> <p>ComPact: drawout NSX250 with earth leakage protection - control: toggle - vertical installation</p> <p>ComPact: drawout NSX250 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: drawout NSX250 with earth leakage protection - control: motor mechanism - vertical installation</p> <p>ComPact: fixed NSX250 with earth leakage protection - control: motor mechanism - vertical installation</p>

Poles description	4 x 3P: mounting plate support: CVS100...160 vertical installation 3 x 4P: mounting plate support: CVS100...160 vertical installation 4 x 3P: mounting plate support: CVS250 vertical installation 3 x 4P: mounting plate support: CVS250 vertical installation 4 x 3P: mounting plate support: NSX100...160 vertical installation 3 x 4P: mounting plate support: NSX100...160 vertical installation 4 x 3P: mounting plate support: NSX250 vertical installation 3 x 4P: mounting plate support: NSX250 vertical installation 2 x 3P: mounting plate support: NSX100...160 vertical installation 2 x 4P: mounting plate support: NSX100...160 vertical installation 2 x 3P: mounting plate support: NSX250 vertical installation 2 x 4P: mounting plate support: NSX250 vertical installation
Operating position	Vertical

Complementary

Enclosure/cubicle description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Cubicle - width 650 mm depth 400 mm
Connection position	Direct connection Linergy FC
Number of vertical modules [50 mm]	7
Standards	IEC 61439-1 IEC 61439-2
Product certifications	ASTA
Material	Steel
Surface finish	Matt Textured
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9003)
Height	350 mm
Width	500 mm
Net weight	1.26 kg

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1.5 cm
Package 1 Width	36.0 cm
Package 1 Length	51.5 cm
Package 1 Weight	1.24 kg
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	17.0 cm
Package 2 Width	40.0 cm
Package 2 Length	53.0 cm
Package 2 Weight	12.9 kg
Unit Type of Package 3	P12
Number of Units in Package 3	40
Package 3 Height	57.5 cm
Package 3 Width	80.0 cm
Package 3 Length	120.0 cm
Package 3 Weight	63.0 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations
PVC free	Yes
Halogen content performance	Halogen free plastic parts product