


# LVS03289

Front plate, PrismaSeT G, for NSX/NSX  
Vigi(ELCB) 400/630, 6M, horizontal, fixed,  
toggle, W850, white, RAL 9003

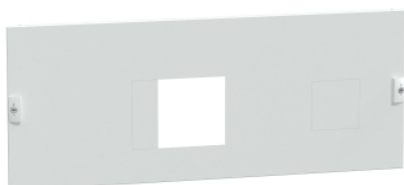

## Main

|                                    |  |
|------------------------------------|--|
| Range                              | PrismaSeT  |
| Range of product                   | PrismaSeT G  |
| Product or component type          | Front plate  |
| Accessory / separate part category | Installation accessory   |
| Range compatibility                | PrismaSeT PrismaSeT G enclosure  |
| Type of front plate                | Cut-out  |
| Installed device                   | ComPact: fixed NSX400 without earth leakage protection - control: toggle - horizontal installation<br>ComPact: fixed NSX630 without earth leakage protection - control: toggle - horizontal installation   |
| Poles description                  | 1 x 3P: mounting plate support: NSX400 horizontal installation<br>1 x 4P: mounting plate support: NSX400 horizontal installation<br>1 x 3P: mounting plate support: NSX630 horizontal installation<br>1 x 4P: mounting plate support: NSX630 horizontal installation |
| Operating position                 | Horizontal   |

## Complementary

|                                    |  |
|------------------------------------|--|
| Enclosure/cubicle description      | Floor-standing enclosure - width 850 mm                              |
| Connection position                | Connection block   |
| Number of vertical modules [50 mm] | 6  |
| Standards                          | IEC 61439-1<br>IEC 61439-2   |
| Product certifications             | ASTA   |
| Surface finish                     | Textured<br>Matt   |
| Protective treatment               | Electrophoresis treatment and hot-polymerised polyester epoxy powder |
| Colour                             | White (RAL 9003)   |
| Height                             | 300 mm   |
| Width                              | 850 mm   |
| Net weight                         | 1.92 kg  |

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

|                  |  |
|------------------|--|
| Quantity per set | Set of 1   |
| Functional unit  | 850 mm PrismaSeT G floor-standing enclosure ComPact NSX400 without fixed toggle horizontal 3P 1 connection block 9<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX400 without fixed toggle horizontal 4P 1 connection block 9<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX400 without fixed toggle horizontal 3P 1 connection block 6<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX400 without fixed toggle horizontal 4P 1 connection block 6<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 3P 1 connection block 9<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 4P 1 connection block 9<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 3P 1 connection block 6<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 4P 1 connection block 6<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX400 without fixed toggle horizontal 3P 1 direct with long terminal shield 9<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX400 without fixed toggle horizontal 4P 1 direct with long terminal shield 9<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX400 without fixed toggle horizontal 3P 1 direct with long terminal shield 6<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX400 without fixed toggle horizontal 4P 1 direct with long terminal shield 6<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 9<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 9<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 3P 1 direct with long terminal shield 6<br>850 mm PrismaSeT G floor-standing enclosure ComPact NSX630 without fixed toggle horizontal 4P 1 direct with long terminal shield 6 |



## Environment

|                         |      |
|-------------------------|------|
| IP degree of protection | IP30 |
|-------------------------|------|

## Packing Units

|                              |          |
|------------------------------|----------|
| Unit Type of Package 1       | PCE      |
| Number of Units in Package 1 | 1        |
| Package 1 Height             | 3.0 cm   |
| Package 1 Width              | 30.0 cm  |
| Package 1 Length             | 75.0 cm  |
| Package 1 Weight             | 1.975 kg |
| Unit Type of Package 2       | BB1      |
| Number of Units in Package 2 | 4        |
| Package 2 Height             | 6.5 cm   |
| Package 2 Width              | 32.0 cm  |
| Package 2 Length             | 78.0 cm  |
| Package 2 Weight             | 8.289 kg |
| Unit Type of Package 3       | P12      |
| Number of Units in Package 3 | 40       |
| Package 3 Height             | 47.0 cm  |
| Package 3 Width              | 80.0 cm  |
| Package 3 Length             | 120.0 cm |
| Package 3 Weight             | 94.5 kg  |

## Offer Sustainability

|                          |  |
|--------------------------|--|
| Sustainable offer status | Green Premium product  |
| REACH Regulation         |  <a href="#">REACH Declaration</a>  |
| REACH free of SVHC       | Yes  |
| EU RoHS Directive        | Pro-active compliance (Product out of EU RoHS legal scope)  <a href="#">EU RoHS Declaration</a> |
| Toxic heavy metal free   | Yes  |

|                             |   |
|-----------------------------|---|
| Mercury free                | Yes   |
| China RoHS Regulation       | <a href="#">China RoHS Declaration</a>        |
| RoHS exemption information  | <a href="#">Yes</a>                           |
| Environmental Disclosure    | <a href="#">Product Environmental Profile</a> |
| Circularity Profile         | No need of specific recycling operations      |
| PVC free                    | Yes   |
| Halogen content performance | Halogen free plastic parts product            |