


LVS03297

Front plate, PrismaSeT P and G, for Vigi NSX
400/600, 9M, vertical, fixed, toggle/rotary
handle, W600, white, RAL 9003

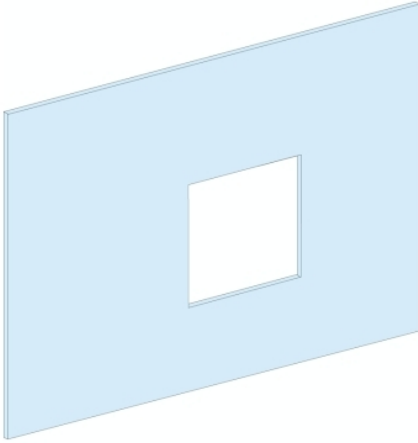



Main

Range	PrismaSeT
Range of product	PrismaSeT G PrismaSeT P
Product or component type	Front plate
Accessory / separate part category	Installation accessory
Range compatibility	PrismaSeT PrismaSeT G enclosure PrismaSeT PrismaSeT P cubicle
Type of front plate	Cut-out
Installed device	<p>ComPact: fixed NSX400 with earth leakage protection - control: toggle - vertical installation</p> <p>EasyPact: fixed CVS400 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>EasyPact: fixed CVS630 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: fixed NSX400 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: plug-in NSX400 with earth leakage protection - control: toggle - vertical installation</p> <p>ComPact: plug-in NSX400 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: drawout NSX400 with earth leakage protection - control: toggle - vertical installation</p> <p>ComPact: drawout NSX400 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: drawout NSX400 with earth leakage protection - control: motor mechanism - vertical installation</p> <p>ComPact: fixed NSX630 with earth leakage protection - control: toggle - vertical installation</p> <p>ComPact: fixed NSX630 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: plug-in NSX630 with earth leakage protection - control: toggle - vertical installation</p> <p>ComPact: plug-in NSX630 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: drawout NSX630 with earth leakage protection - control: toggle - vertical installation</p> <p>ComPact: drawout NSX630 with earth leakage protection - control: direct front rotary handle - vertical installation</p> <p>ComPact: drawout NSX630 with earth leakage protection - control: motor mechanism - vertical installation</p>
Poles description	<p>1 x 4P: mounting plate support: NSX400 vertical installation</p> <p>1 x 3P: mounting plate support: CVS400 vertical installation</p> <p>1 x 4P: mounting plate support: CVS400 vertical installation</p> <p>1 x 3P: mounting plate support: CVS630 vertical installation</p> <p>1 x 4P: mounting plate support: CVS630 vertical installation</p> <p>1 x 3P: mounting plate support: NSX400 vertical installation</p> <p>1 x 3P: mounting plate support: NSX630 vertical installation</p> <p>1 x 4P: mounting plate support: NSX630 vertical installation</p>
Operating position	Vertical

Complementary

Enclosure/cubicle description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Cubicle - width 650 mm depth 400 mm
Connection position	Linery FC Direct connection
Number of vertical modules [50 mm]	11
Standards	IEC 61439-1 IEC 61439-2
Product certifications	ASTA
Material	Steel
Surface finish	Matt Textured
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9003)
Height	550 mm
Width	500 mm
Net weight	2.08 kg

Environment

IP degree of protection	IP30
-------------------------	------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.000 cm
Package 1 Width	51.500 cm
Package 1 Length	56.500 cm
Package 1 Weight	2.063 kg
Unit Type of Package 2	BB1
Number of Units in Package 2	6
Package 2 Height	16.500 cm
Package 2 Width	51.000 cm
Package 2 Length	80.000 cm
Package 2 Weight	13.358 kg
Unit Type of Package 3	P12
Number of Units in Package 3	48
Package 3 Height	78.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	119.000 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations
PVC free	Yes
Halogen content performance	Halogen free plastic parts product