


LVS03412

Mounting Plate, PrismaSeT P, VIGI NSX/ CVS 250A 4P toggle horizontal fixed, enclosure W650mm

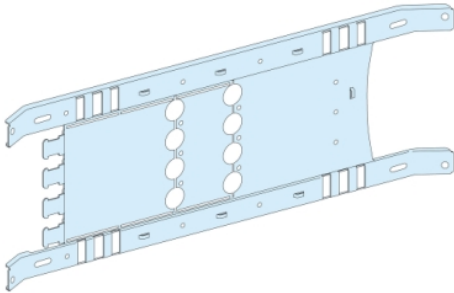

Main

Range	PrismaSeT
Range of product	PrismaSeT P
Product or component type	Mounting plate
Accessory / separate part category	Installation accessory
Range compatibility	PrismaSeT PrismaSeT P cubicle
Installation description	Cubicle - width 650 mm depth 400 mm
Installed device	EasyPact: fixed CVS100...160 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS250 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed INS250 - control: direct front rotary handle - horizontal installation ComPact: fixed INV250 - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX250 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS100...160 with earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS250 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX100...160 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX250 with earth leakage protection - control: toggle - horizontal installation
Poles description	1 x 4P: fixed CVS100...160 horizontal installation 1 x 4P: fixed CVS250 horizontal installation 1 x 3P: fixed INS250 horizontal installation 1 x 4P: fixed INS250 horizontal installation 1 x 3P: fixed INV250 horizontal installation 1 x 4P: fixed INV250 horizontal installation 1 x 4P: fixed NSX100...160 horizontal installation 1 x 4P: fixed NSX250 horizontal installation
Number of vertical modules [50 mm]	4 module(s): CVS100...160 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): CVS250 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): INS250, direct in 650 mm Widecubicle 4 module(s): INV250, direct in 650 mm Widecubicle 4 module(s): NSX100...160 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): NSX250 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): CVS100...160 with earth leakage protection , direct in 650 mm Widecubicle 4 module(s): CVS250 with earth leakage protection , direct in 650 mm Widecubicle 4 module(s): NSX100...160 with earth leakage protection , direct in 650 mm Widecubicle 4 module(s): NSX250 with earth leakage protection , direct in 650 mm Widecubicle
Standards	IEC 61439-2
Product certifications	ASTA

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.



Complementary

Material	Sheet steel
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface finish	Textured Matt
Colour	White (RAL 9003)
Width	650 mm
Height	192 mm
Net weight	1.48 kg
Functional unit	650 mm 400 mm PrismaSeT P cubicle EasyPact CVS100...160 without fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle EasyPact CVS250 without fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle ComPact INS250 fixed direct front rotary handle horizontal 3P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle ComPact INS250 fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle ComPact INV250 fixed direct front rotary handle horizontal 3P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle ComPact INV250 fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle ComPact NSX100...160 without fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle ComPact NSX250 without fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle EasyPact CVS100...160 with fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle EasyPact CVS250 with fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle ComPact NSX100...160 with fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm PrismaSeT P cubicle ComPact NSX250 with fixed toggle horizontal 4P 1 direct 4 12.5 mm

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.5 cm
Package 1 Width	19.5 cm
Package 1 Length	57.7 cm
Package 1 Weight	1.454 kg
Unit Type of Package 2	CAR
Number of Units in Package 2	5
Package 2 Height	22.5 cm
Package 2 Width	22 cm
Package 2 Length	61.2 cm
Package 2 Weight	7.661 kg
Unit Type of Package 3	P12
Number of Units in Package 3	100
Package 3 Height	103 cm
Package 3 Width	80 cm
Package 3 Length	120 cm
Package 3 Weight	164 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Toxic heavy metal free	Yes

Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations
PVC free	Yes
Halogen content performance	Halogen free plastic parts product