


# LVS04753

Insulated flexible bar, PrismaSeT P and G, 660 A, busbar size 32 x 8mm, length 1800mm, set of 1

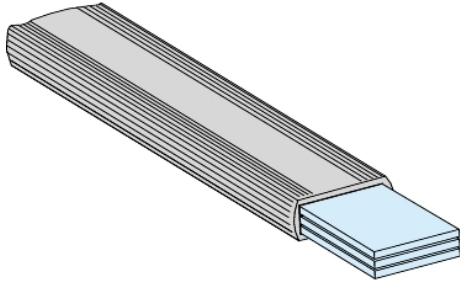

## Main

Range	PrismaSeT
Range of product	PrismaSeT G PrismaSeT P
Product or component type	Insulated flexible bar
Product name	PrismaSeT PrismaSeT G enclosure PrismaSeT PrismaSeT P enclosure PrismaSeT Prisma iPM L enclosure PrismaSeT Prisma iPM M enclosure
Accessory / separate part category	Current distribution accessory
Standards	IEC 61439-2, inside enclosure IEC 61439-1, inside enclosure
Product certifications	ASTA

## Complementary

Installation description	Cubicle Floor-standing enclosure Wall-mounted enclosure
Installed device	ComPact: NSX630 ComPact: CVS630
[Ie] rated operational current	660 A
Busbar cross section	32 x 8 mm
Length	1800 mm
Net weight	4.88 kg
Quantity per set	Set of 1

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.0 cm
Package 1 Width	11.5 cm
Package 1 Length	194.0 cm
Package 1 Weight	4.827 kg
Unit Type of Package 2	P2M
Number of Units in Package 2	100
Package 2 Height	29.0 cm
Package 2 Width	120.0 cm
Package 2 Length	200.0 cm
Package 2 Weight	501.0 kg

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations