


LVS04964

Partition Plate, PrismaSeT P, form 2, 4M, front and rear horizontal partition, for enclosures W400, D600

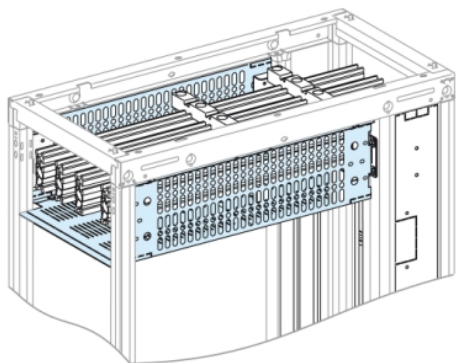

Main

Range	PrismaSeT
Range of product	PrismaSeT P
Product or component type	Partition
Accessory / separate part category	Insulation accessory
Range compatibility	PrismaSeT PrismaSeT P enclosure Linergy Linergy BS busbar Linergy Linergy LGYE busbar
Product specific application	To partition horizontal busbars
Cubicle partitioning form	Form 2

Complementary

Enclosure/cubicle width	400 mm
Enclosure/cubicle description	Cubicle 4000A
Installation description	Cubicle 4000A - width 400 mm, depth 600 mm
Product destination	For 600 mm deep framework
Cubicle depth	600 mm
Height	200 mm
Colour	White (RAL 9003)
Surface finish	Powder coated Textured Matt
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Net weight	2.64 kg

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.5 cm
Package 1 Width	34.5 cm
Package 1 Length	41.5 cm
Package 1 Weight	2.515 kg
Unit Type of Package 2	P06
Number of Units in Package 2	44
Package 2 Height	73.0 cm
Package 2 Width	60.0 cm
Package 2 Length	80.0 cm
Package 2 Weight	133.0 kg

The information provided in this documentation contains general descriptions and/or technical characteristics of the products of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations
PVC free	Yes
Halogen content performance	Halogen free plastic parts product