


# Product data sheet

## Characteristics

# LVS08898

Gland plate, PrismaSeT G, knockouts type, 39 inlet with dia 7 to 26MM, Insulated, direct mounting, IP55, white, RAL 9003

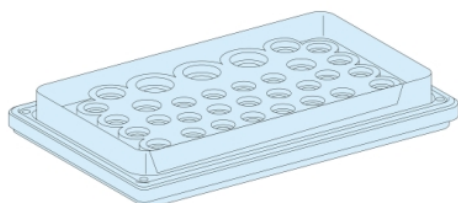

### Main

Range of product	PrismaSeT G
Range	PrismaSeT
Range compatibility	PrismaSeT PrismaSeT G enclosure
Product or component type	Gland plate
Accessory / separate part category	Enclosure accessory
Product compatibility	IP55 enclosure

### Complementary

Enclosure/cubicle description	Wall-mounted enclosure - width 600 mm
Type of gland plate	Knockouts
Mounting location	Bottom Top
Material	Insulated material
Cable entry number	39 diameter: 7...26 mm
Quantity per set	Set of 1
Depth	180 mm
Net weight	0.36 kg
Colour	White (RAL 9003)

### Environment

IP degree of protection	IP55
-------------------------	------

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.200 cm
Package 1 Width	16.100 cm
Package 1 Length	25.000 cm
Package 1 Weight	352.000 g
Unit Type of Package 2	BB1
Number of Units in Package 2	40
Package 2 Height	35.000 cm
Package 2 Width	34.000 cm
Package 2 Length	68.500 cm
Package 2 Weight	16.373 kg
Unit Type of Package 3	P12
Number of Units in Package 3	240
Package 3 Height	85.000 cm
Package 3 Width	80.000 cm

Package 3 Length	120.000 cm
Package 3 Weight	103.500 kg

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations
PVC free	Yes
Halogen content performance	Halogen free plastic parts product