


NSYSPF10100

Front & rear plinth, PanelSeT SFN, Spacial SF, Spacial SM, for electrical enclosure W1000mm, plinth H100mm

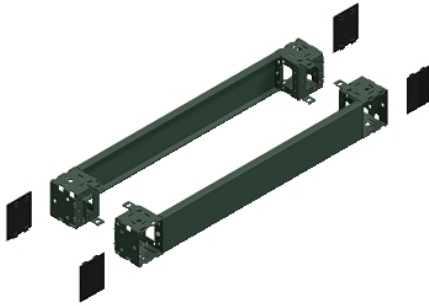

Main

Range	Spacial
Accessory / separate part category	Enclosure accessory
Product or component type	Plinth front
Application	Multi-purpose
Nominal dimensions of the housing	-
Device composition	Fixing elements 4 corner cover 1 front panel 1 rear panel 4 corner
Range compatibility	Spacial Spacial SF Spacial Spacial SM Spacial Spacial SD Spacial Spacial S3D
Mounting support	Plinth side panels

Complementary

Fixing mode	By fixing element - on structure location
Colour	Grey (RAL 7022)
Surface finish	Epoxy-polyester powder
Permanent permissible load	1300 kg
Height	100 mm
Width	1000 mm nominal:

Environment

IP degree of protection	IP20 (complete plinth)
IK degree of protection	IK10

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	11.500 cm
Package 1 Width	20.000 cm
Package 1 Length	102.000 cm
Package 1 Weight	5.487 kg
Unit Type of Package 2	PAM
Number of Units in Package 2	40
Package 2 Height	90.000 cm
Package 2 Width	100.000 cm
Package 2 Length	120.000 cm
Package 2 Weight	232.480 kg

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 months
----------	-----------