


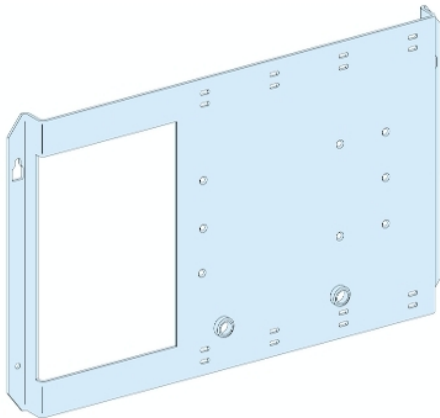



Main

Range	Prisma
Range of product	Prisma G
Product or component type	Mounting plate
Accessory / separate part category	Installation accessory
Range compatibility	Prisma Prisma G enclosure
Installation description	Floor-standing enclosure - width 850 mm Floor-standing enclosure + duct - width 600 + 300 mm Wall-mounted enclosure + duct - width 600 + 300 mm
Installed device	EasyPact: fixed CVS400 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS630 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed EZC400 - control: toggle - horizontal installation EasyPact: fixed EZC630 - control: toggle - horizontal installation ComPact: fixed INS320...400 - control: direct front rotary handle - horizontal installation ComPact: fixed INS500...630 - control: direct front rotary handle - horizontal installation ComPact: fixed INV320...400 - control: direct front rotary handle - horizontal installation ComPact: fixed INV500...630 - control: direct front rotary handle - horizontal installation ComPact: fixed NSX400 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX630 without earth leakage protection - control: toggle - horizontal installation
Poles description	1 x 3P: fixed CVS400 horizontal installation 1 x 4P: fixed CVS400 horizontal installation 1 x 3P: fixed CVS630 horizontal installation 1 x 4P: fixed CVS630 horizontal installation 1 x 3P: fixed EZC400 horizontal installation 1 x 4P: fixed EZC400 horizontal installation 1 x 3P: fixed EZC630 horizontal installation 1 x 4P: fixed EZC630 horizontal installation 1 x 3P: fixed INS320...400 horizontal installation 1 x 4P: fixed INS320...400 horizontal installation 1 x 3P: fixed INS500...630 horizontal installation 1 x 4P: fixed INS500...630 horizontal installation 1 x 3P: fixed INV320...400 horizontal installation 1 x 4P: fixed INV320...400 horizontal installation 1 x 3P: fixed INV500...630 horizontal installation 1 x 4P: fixed INV500...630 horizontal installation 1 x 3P: fixed NSX400 horizontal installation 1 x 4P: fixed NSX400 horizontal installation 1 x 3P: fixed NSX630 horizontal installation 1 x 4P: fixed NSX630 horizontal installation
Condition of using cable tie	Need additional plate (2M high) when installation of device is in horizontal

Standards	IEC 61439-2
Product certifications	ASEFA

Complementary

Cable entry	Cut-out plates 0.38 mm top 217 mm Cut-out plates 0.32 mm bottom 67 mm
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface finish	Smooth Matt
Colour	White (RAL 9001)
Width	600 mm
Height	250 mm

Net weight	2.24 kg
------------	---------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.900 cm
Package 1 Width	29.000 cm
Package 1 Length	47.000 cm
Package 1 Weight	2.300 kg
Unit Type of Package 2	S04
Number of Units in Package 2	8
Package 2 Height	30.000 cm
Package 2 Width	40.000 cm
Package 2 Length	60.000 cm
Package 2 Weight	19.050 kg
Unit Type of Package 3	P12
Number of Units in Package 3	96
Package 3 Height	105.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	225.840 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Halogen content performance	Halogen free plastic parts product